


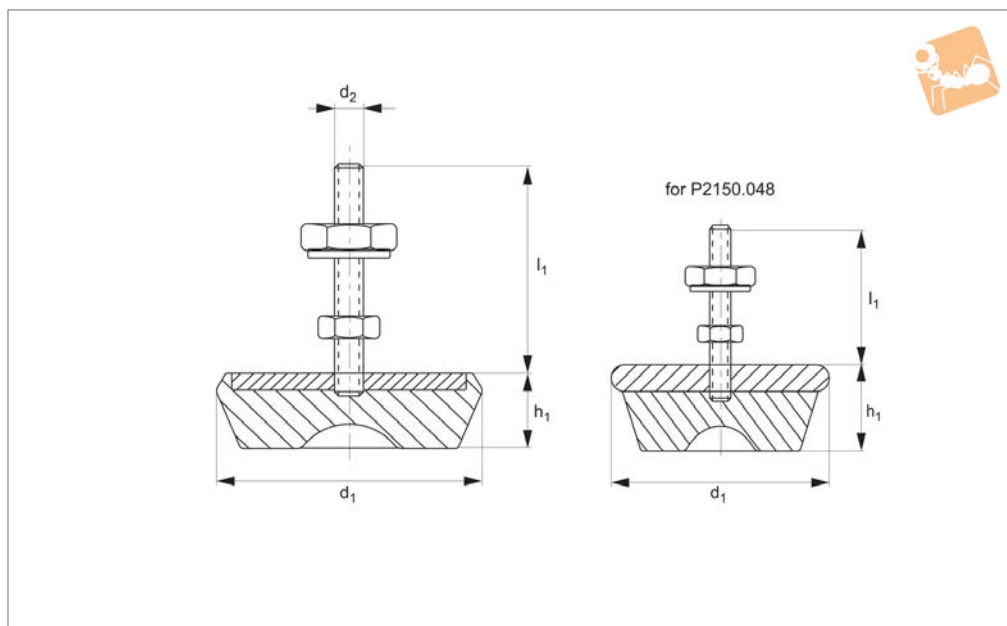

P2150

LEVELLING FEET

Material

Steel body with silver zinc plated thread.
Synthetic rubber pad (65-70 Shore A) with

anti-slide cavity.

vibrations and for irregular floors.

Technical Notes

Suitable for machinery with low frequency

Order No.	d_1	h_1	d_2	l_1	Load range kgf
P2150.048	48	23	M 8	40	0-80
P2150.060	60	25	M10	83	50-120
P2150.075	75	30	M12	90	80-150
P2150.090	90	33	M12	90	120-300
P2150.105	105	38	M16	110	250-500
P2150.125	125	45	M16	110	400-800
P2150.150	150	55	M16	110	600-1000
P2150.170	170	57	M16	110	1000-1600
P2150.187	187	70	M20	115	1400-2400
P2150.210	210	75	M20	115	2000-3500

