




3-D Pulleys - aluminium, hubless

4mm nominal circular pitch

Chains, Belts & Pulleys

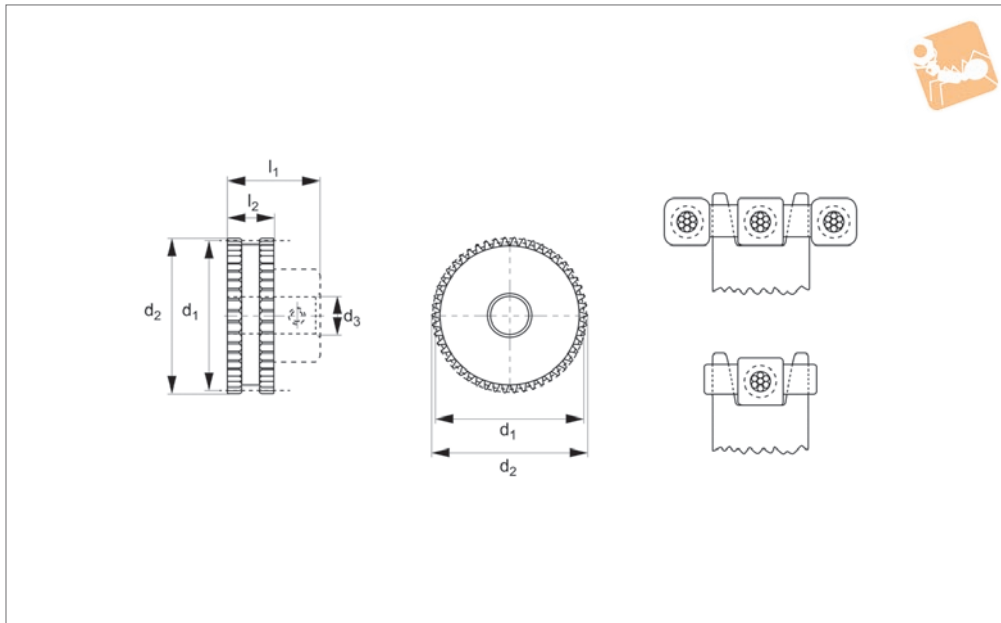

R1052

CHAINS, BELTS & PULLEYS

Material

Aluminium DIN 3,1355 anodized.

Stainless steel equivalent available.

Technical Notes

Other no's of teeth available on request.

Important Notes

Operate with R1050 series chain.

Order No.	No. of teeth	Pitch dia.	Outside dia.
R1052.A014-H	14	17.76	19.34
R1052.A015-H	15	19.03	20.61
R1052.A016-H	16	20.29	21.87
R1052.A017-H	17	21.56	23.14
R1052.A018-H	18	22.83	24.41
R1052.A019-H	19	24.10	25.68
R1052.A020-H	20	25.37	26.95
R1052.A022-H	22	27.90	29.48
R1052.A024-H	24	30.44	32.02
R1052.A025-H	25	31.71	33.26
R1052.A026-H	26	32.98	34.56
R1052.A028-H	28	35.51	37.09
R1052.A030-H	30	38.05	39.63
R1052.A032-H	32	40.59	42.17
R1052.A035-H	35	44.39	45.97
R1052.A036-H	36	45.66	47.24
R1052.A040-H	40	50.47	52.32
R1052.A045-H	45	57.10	58.66
R1052.A050-H	50	63.41	65.00
R1052.A055-H	55	69.76	71.34
R1052.A060-H	60	76.10	77.68
R1052.A065-H	65	82.45	84.02
R1052.A070-H	70	88.79	90.37
R1052.A075-H	75	95.13	96.71
R1052.A080-H	80	101.47	103.05