




Timing Belts MXL - 2mm nominal 3mm wide

Chains, Belts & Pulleys

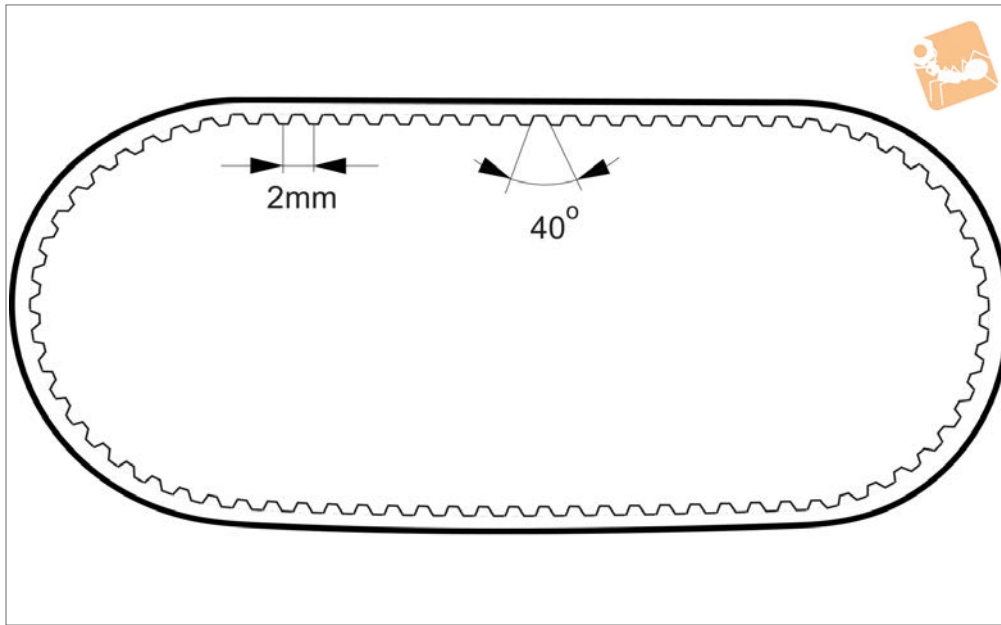

R1430.1

CHAINS, BELTS & PULLEYS

Material

Neoprene (black). Fibreglass reinforced.

Technical Notes

High Ratios.
Allows use of small diameter pulleys.
High speeds.

High power transmission.

Long life.

Wear resistant nylon facing.

Low profile.

Quiet operation.

Max speed up to 20,000 rpm.

Minimum pulley diameter 6,4 (10 grooves).

Temperature range +85°C to -34°C.

Important Notes

Operates with TP3 (R1430) pulleys.

Order No.	No. of grooves	Length ref.
TB7EF2-40	40	81.3
TB7EF2-42	42	85.3
TB7EF2-45	45	91.4
TB7EF2-50	50	101.6
TB7EF2-54	54	109.7
TB7EF2-55	55	111.8
TB7EF2-57	57	115.8
TB7EF2-60	60	121.9
TB7EF2-64	64	130.0
TB7EF2-67	67	136.1
TB7EF2-70	70	142.2
TB7E2-73	73	148.3
TB7EF2-80	80	162.6
TB7EF2-90	90	182.9
TB7EF2-100	100	203.2
TB7EF2-105	105	213.4
TB7EF2-110	110	223.5
TB7EF2-120	120	243.8
TB7EF2-130	130	264.2
TB7EF2-150	150	304.8
TB7EF2-160	160	325.1
TB7EF2-170	170	345.4
TB7EF2-175	175	355.6
TB7EF2-190	190	386.1
TB7EF2-200	200	406.4
TB7EF2-225	225	457.2
TB7EF2-250	250	508.0
TB7EF2-300	300	609.6
TB7EF2-400	400	812.8