




Spur Gears

Stainless Steel

Standard Spur Gears

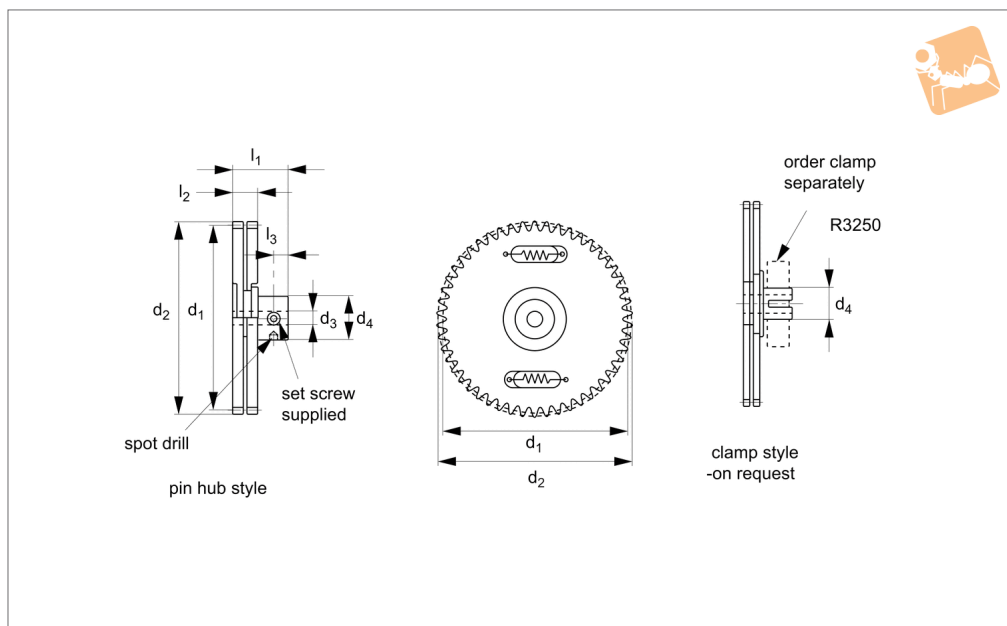

R2084

STANDARD SPUR GEARS

Material
A2 Stainless

Quality class DIN 7, AGMA 10.

pressure angle, quality class DIN 5 & 3 etc).

Technical Notes
20° pressure angle.

Tips
Special versions available on request
(e.g. different number of teeth, 14.5°

Order No.	No. of teeth	d_1 p.d.	d_2	d_3	d_4	w_1	w_2
R2084.018-12-SS	18	12	20	27.0	30.0	25	12
R2084.020-12-SS	20	12	20	30.0	33.0	25	12
R2084.024-12-SS	24	12	20	36.0	39.0	25	12
R2084.028-12-SS	28	12	20	42.0	45.0	25	12
R2084.030-12-SS	30	12	20	45.0	48.0	25	12
R2084.032-12-SS	32	12	20	48.0	51.0	25	12
R2084.036-12-SS	36	12	20	54.0	57.0	25	12
R2084.040-12-SS	40	12	20	60.0	63.0	25	12
R2084.042-12-SS	42	12	20	63.0	66.0	25	12
R2084.045-12-SS	45	12	20	67.5	70.5	25	12
R2084.048-12-SS	48	12	20	72.0	75.0	25	12
R2084.050-12-SS	50	12	20	75.0	78.0	25	12
R2084.056-12-SS	56	12	20	84.0	87.0	25	12
R2084.060-12-SS	60	12	20	90.0	93.0	25	12
R2084.064-12-SS	64	12	20	96.0	99.0	25	12