




1,5 Module Helical Gears

stainless steel, pin hub

Other Precision
Gears

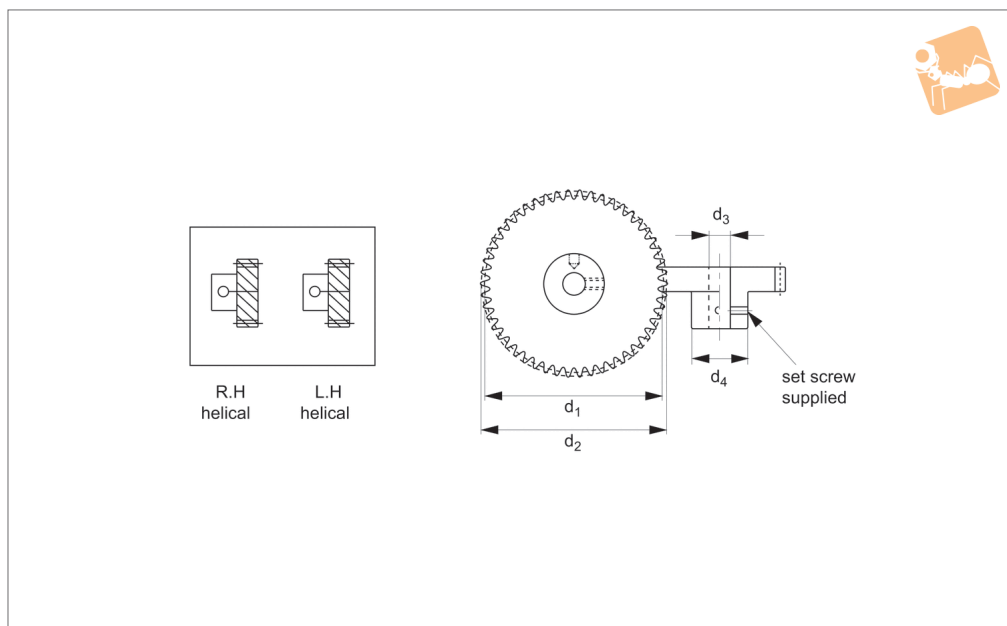

R2152

OTHER PRECISION GEARS

Material

Stainless steel (DIN 1,4305).

20° pressure angle.

Quality class DIN 8, AGMA 9.

with same helical direction.

For parallel transmission use right and left helix.

Technical Notes

45° helix angle.

Tips

For right angle transmission use two gears

Order No.	Hand	No. of teeth	Pitch dia. P.D.	O.D. dia.
R2152.R012	Right	12	25.46	28.46
R2152.R016	Right	16	33.94	36.94
R2152.R020	Right	20	42.43	45.43
R2152.L012	Left	12	25.46	28.46
R2152.L016	Left	16	33.94	36.94
R2152.L020	Left	20	42.43	45.43
R2152.R024	Right	24	50.91	53.91
R2152.L024	Left	24	50.91	53.91
R2152.R032	Right	32	67.88	70.88
R2152.R040	Right	40	84.85	87.85
R2152.R048	Right	48	101.82	104.82
R2152.L032	Left	32	67.88	70.88
R2152.L040	Left	40	84.85	87.85
R2152.L048	Left	48	101.82	104.82