




0,5 Module Right Hand Helical Gears

stainless steel pin hub

Other Precision
Gears

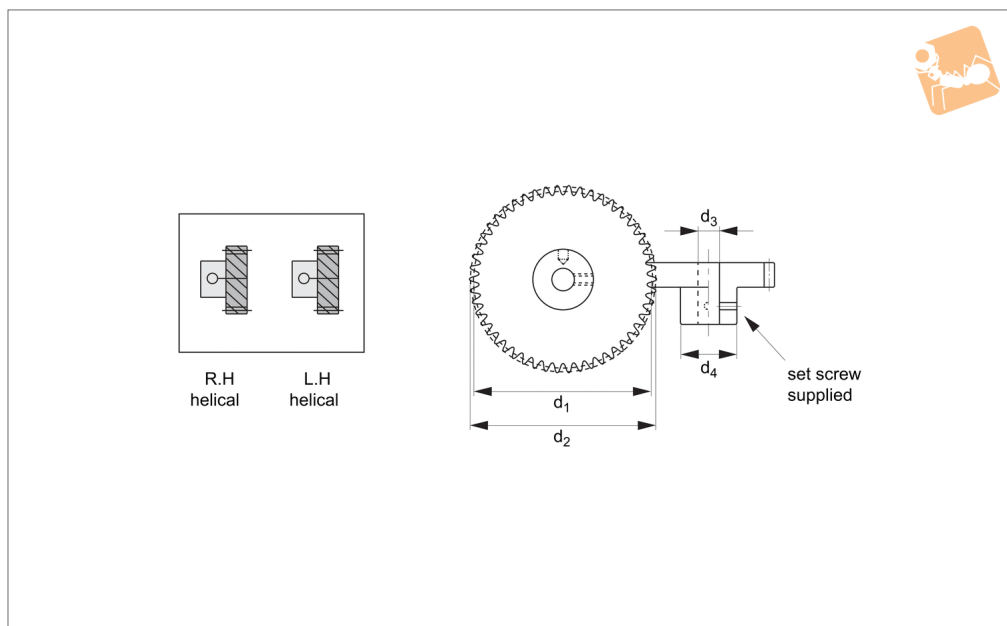

R2160

OTHER PRECISION GEARS

Material

Stainless steel (DIN 1,4305).

Technical Notes

45° helix angle.

20° pressure angle.

Quality class DIN 7, AGMA 10.

Tips

For right angle transmission use two gears with same helical direction. For parallel transmission use right and left helix.

Important Notes

For 0,5 module left hand helical gears see R2161.


Order No.	Hand	No. of teeth	Material	Bore dia.	Pitch dia. P.D.	Outside dia.
R2160.R020-05	Right	20	Stainless	5	14.14	15.14
R2160.R024-05	Right	24	Stainless	5	16.97	17.97
R2160.R025-05	Right	25	Stainless	5	17.68	18.68
R2160.R030-05	Right	30	Stainless	5	21.21	22.21
R2160.R035-05	Right	35	Stainless	5	24.75	25.75
R2160.R036-05	Right	36	Stainless	5	25.46	26.46
R2160.R040-05	Right	40	Stainless	5	28.28	29.28
R2160.R045-05	Right	45	Stainless	5	31.82	32.82
R2160.R048-05	Right	48	Stainless	5	33.94	34.94
R2160.R050-05	Right	50	Stainless	5	35.36	36.36
R2160.R060-05	Right	60	Stainless	5	42.43	43.43
R2160.R070-05	Right	70	Stainless	5	49.50	50.50
R2160.R072-05	Right	72	Stainless	5	50.91	51.91
R2160.R080-05	Right	80	Stainless	5	56.57	57.57
R2160.R090-05	Right	90	Stainless	5	63.64	64.64
R2160.R096-05	Right	96	Stainless	5	67.88	68.88
R2160.R100-05	Right	100	Stainless	5	70.71	71.71
R2160.R120-05	Right	120	Stainless	5	84.85	85.85
R2160.R144-05	Right	144	Stainless	5	101.82	102.82
R2160.R020-08	Right	20	Stainless	8	14.14	15.14
R2160.R024-08	Right	24	Stainless	8	16.97	17.97
R2160.R025-08	Right	25	Stainless	8	17.68	18.68
R2160.R030-08	Right	30	Stainless	8	21.21	22.21
R2160.R035-08	Right	35	Stainless	8	24.75	25.75
R2160.R036-08	Right	36	Stainless	8	25.46	26.46
R2160.R040-08	Right	40	Stainless	8	28.28	29.28
R2160.R045-08	Right	45	Stainless	8	31.82	32.82
R2160.R048-08	Right	48	Stainless	8	33.94	34.94
R2160.R050-08	Right	50	Stainless	8	35.36	36.36
R2160.R060-08	Right	60	Stainless	8	42.43	43.43
R2160.R070-08	Right	70	Stainless	8	49.50	50.50
R2160.R072-08	Right	72	Stainless	8	50.91	51.91
R2160.R080-08	Right	80	Stainless	8	56.57	57.57



Automotion
AN ESSENTA COMPANY

0333 207 4498

sales@automotioncomponents.co.uk

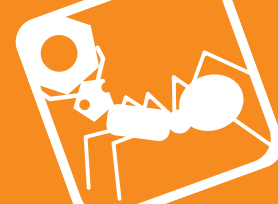

Order No.	Hand	No. of teeth	Material	Bore dia.	Pitch dia. P.D.	Outside dia.
R2160.R090-08	Right	90	Stainless	8	63.64	64.64
R2160.R096-08	Right	96	Stainless	8	67.88	68.88
R2160.R100-08	Right	100	Stainless	8	70.71	71.71
R2160.R120-08	Right	120	Stainless	8	84.85	85.85
R2160.R144-08	Right	144	Stainless	8	101.82	102.82