




1,5/0,25 Module Precision Racks

stainless

Other Precision
Gears

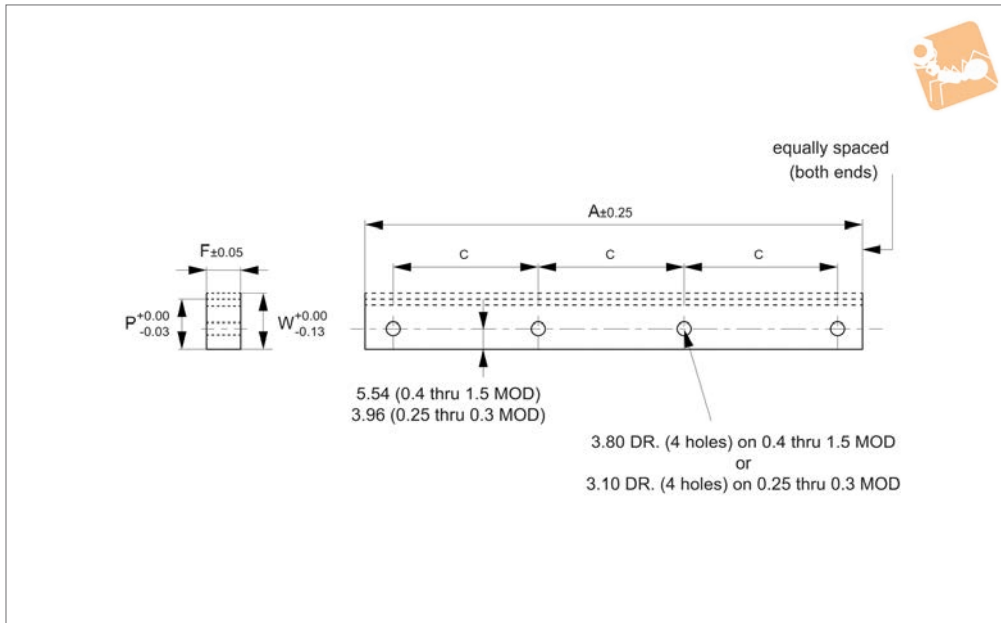

R2174

OTHER PRECISION GEARS

Material

Stainless Steel (DIN 1,4005).

Technical Notes

20° pressure angle.

Quality class Din 7/AGMA 10.

Order No.	Module	a	f	c	P ref.	w
R4M-5	1.5	249.8	5.8	80.0	10.7	12.2
R4M-9	1.25	247.4	5.8	80.0	10.9	12.2
R4M-11	1.0	248.2	5.8	80.0	11.2	12.2
R4M-15	0.8	248.8	5.8	80.0	11.4	12.2
R4M-17	0.6	224.3	5.8	70.0	11.6	12.2
R4M-19	0.5	224.7	5.8	70.0	11.7	12.2
R4M-21	0.4	174.7	5.8	55.0	11.8	12.2
R4M-23	0.3	124.4	4.2	35.0	8.7	9.0
R4M-25	0.25	74.6	4.2	20.0	8.8	9.0