




Stainless Right Angle Drives - 2

Ø15 shafts

Right Angle Gear Boxes

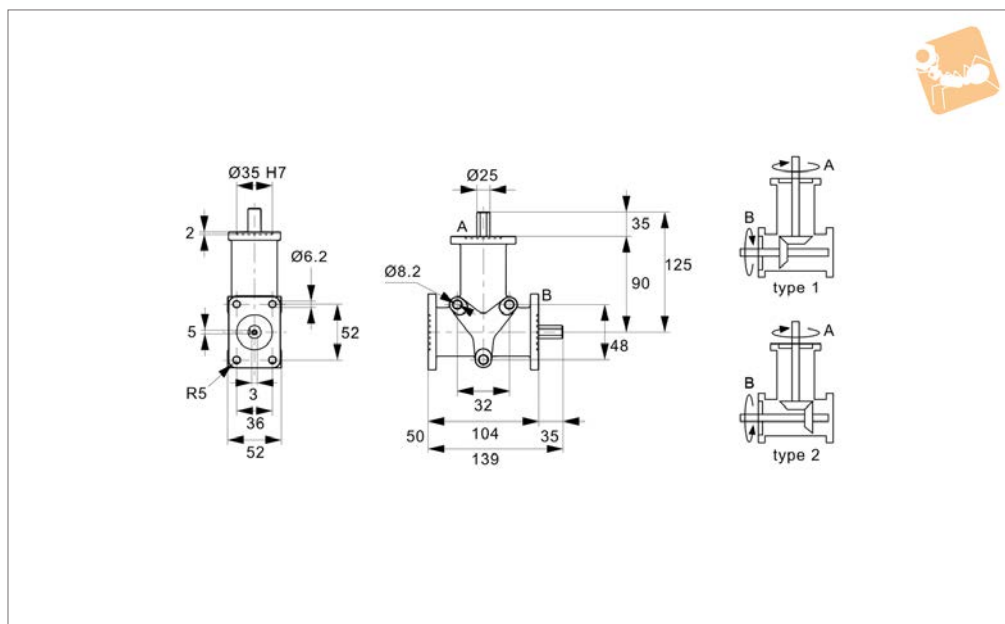

R2352

RIGHT ANGLE GEAR BOXES

Material

Stainless steel (AISI 316) housing and shafts, seals - NBR. Spiral bevel gears from hardened steel.

Shafts are key-wayed.

Technical Notes

Normally used as speed reducers.

Max. radial loading 140N. Max. axial loading 50N.

Angular alignment: 15' to 30' of arc.

Order No.	Shaft dia. tol. f7	Type	Ratio	Input shaft A kW max.	Output shaft B Nm max.	Weight kg
R2352.1-1	15	1	1:1	0.88	6	1.8
R2352.2-1	15	2	1:1	0.880	6	1.8
R2352.1-2	15	1	2:1	0.59	4	1.8
R2352.2-2	15	2	2:1	0.59	4	1.8