




Stainless Right Angle Drives - 2

Ø20 shafts

Right Angle Gear Boxes

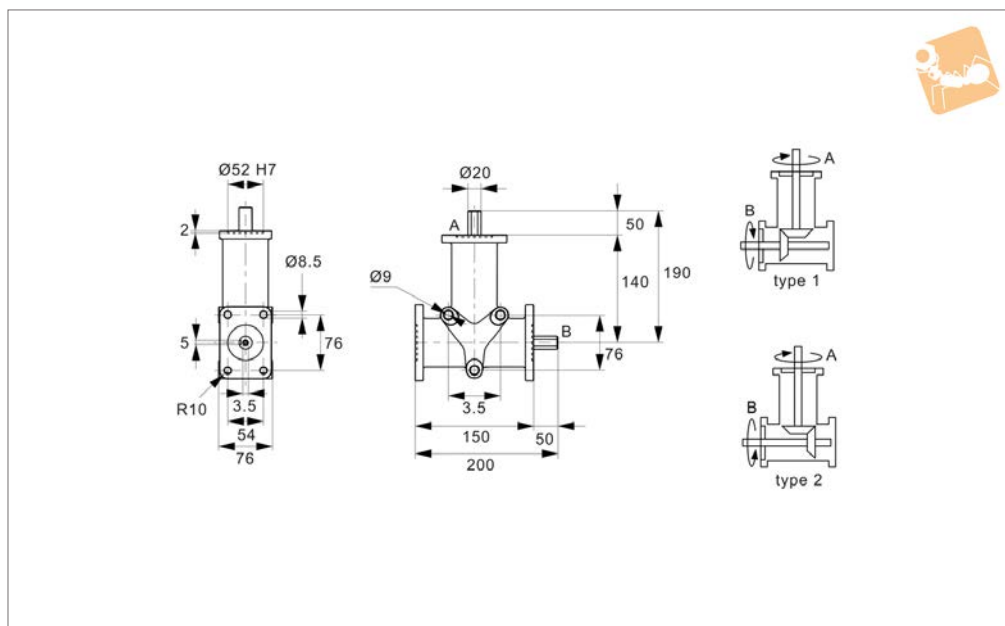

R2354

RIGHT ANGLE GEAR BOXES

Material

Stainless steel (AISI 316) housing and shafts, seals - NBR. Spiral bevel gears from hardened steel. Shafts are key-wayed.

Technical Notes

Normally used as speed reducers.
Max. radial loading 300N. Max. axial

loading 80N.

Angular alignment: 15' to 30' of arc.

Order No.	Shaft dia. tol. f7	Type	Ratio	Input shaft A kW max.	Output shaft B Nm max.	Weight kg
R2354.1-1	20	1	1:1	2.79	19	5.39
R2354.2-1	20	2	1:1	2.79	19	5.39
R2354.1-2	20	1	2:1	1.76	12	5.39
R2354.2-2	20	2	2:1	1.76	12	5.39