




Stainless Right Angle Drives - 3 shafts

Ø20 shafts

Right Angle Gear Boxes

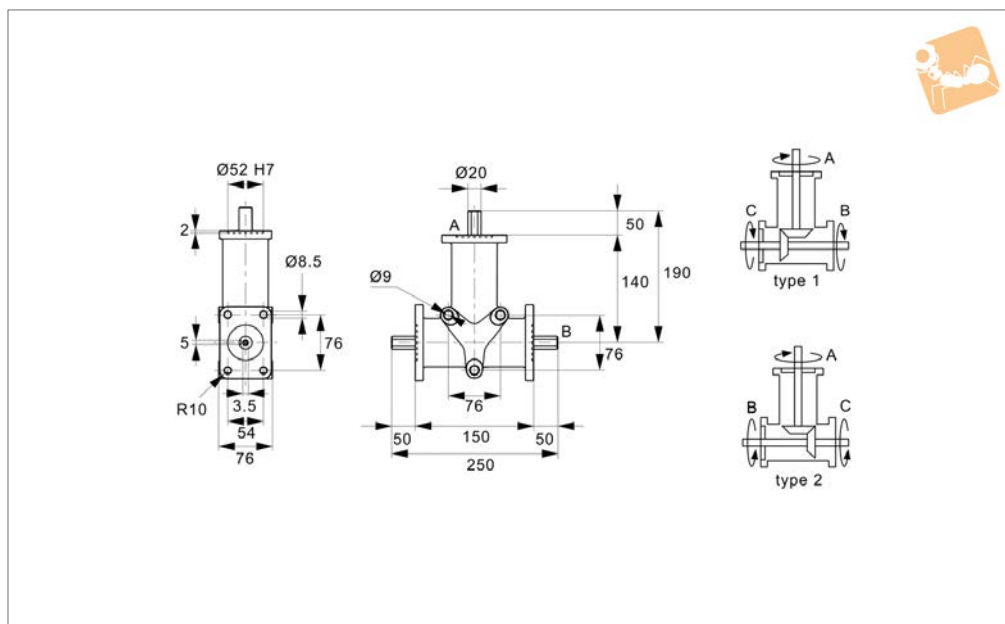

R2355

RIGHT ANGLE GEAR BOXES

Material

Stainless steel (AISI 316) housing and shafts, seals - NBR. Spiral bevel gears from hardened steel. Shafts are key-wayed.

Technical Notes

Normally used as speed reducers.
Max. radial loading 300N. Max. axial

loading 80N.

Angular alignment: 15' to 30' of arc.

Order No.	Shaft dia. tol. f7	Ratio	Input shaft A kW max.	Output shaft B Nm max.	Output shaft C Nm max.	Weight kg
R2355.1	20	1:1	2.79	9.5	9.5	5.54
R2355.2	20	2:1	1.76	6.0	6.0	5.54