




# Stainless Right Angle Drives - 3

Ø25 shafts

## Right Angle Gear Boxes

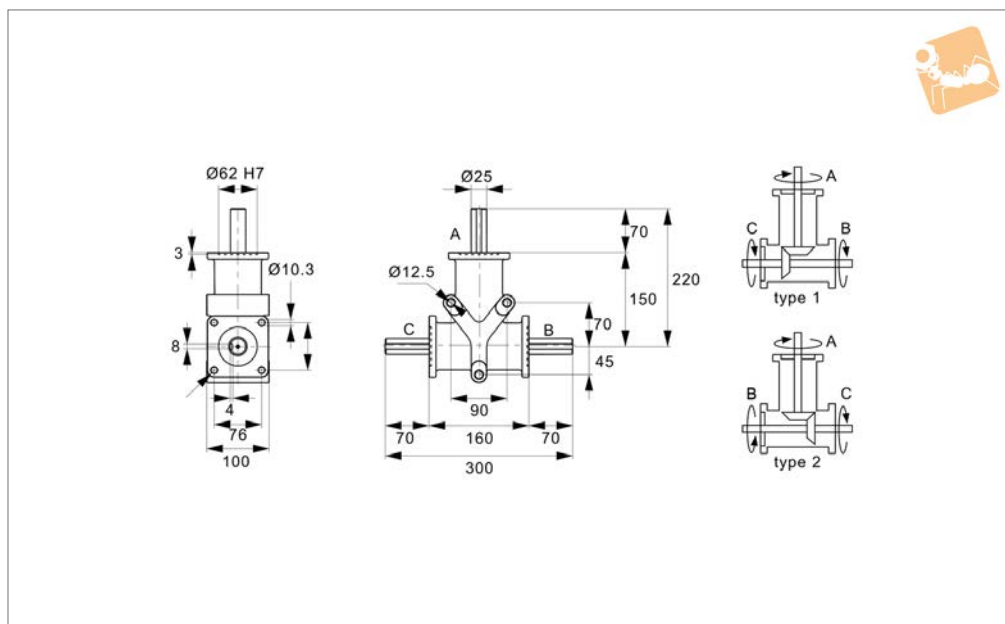

**R2359**

RIGHT ANGLE GEAR BOXES

### Material

Stainless steel (AISI 316) housing and shafts, seals - NBR. Spiral bevel gears from hardened steel. Shafts are key-wayed.

### Technical Notes

Normally used as speed reducers.  
Max. radial loading 400N. Max. axial

loading 160N.

Angular alignment: 15' to 30' of arc.

| Order No. | Shaft dia. | Ratio | Input shaft A<br>kW<br>max. | Output shaft B<br>Nm<br>max. | Output shaft C<br>Nm<br>max. | Weight<br>kg |
|-----------|------------|-------|-----------------------------|------------------------------|------------------------------|--------------|
| R2359.1   | 25         | 1     | 4.55                        | 15.50                        | 15.50                        | 9.45         |
| R2359.2   | 25         | 2     | 3.37                        | 11.50                        | 11.50                        | 9.45         |