



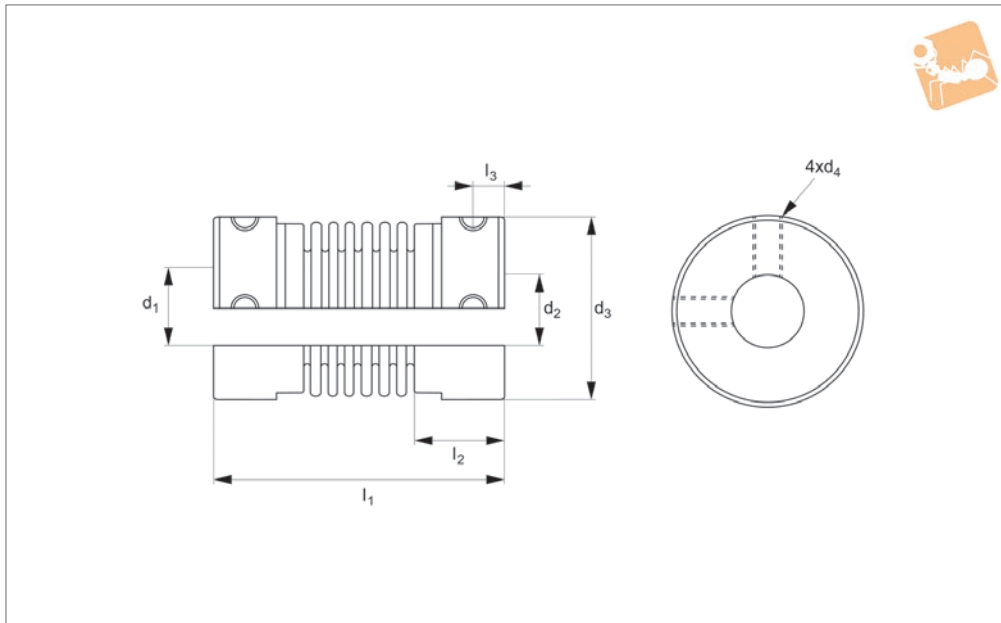

Full Bellows Coupling - Stainless Steel set screw

Flexible Couplings

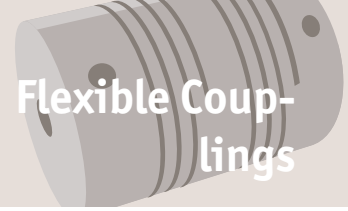

R3011

FLEXIBLE COUPLINGS

Material

Mainframe: Stainless steel SUS303
Bellows: Stainless steel SUS316

tion are individual allowed value, so couple reasons of axial offset appearing at same time would reduce the unit allowable value.

Technical Notes

Offset of angular, parallel or axial devia-

Order No.	d ₁ & d ₂ tol. h8	d ₃	d ₄	l ₁	l ₂	l ₃	Clamping screw lock torque Nm
R3011.A-3	3	12	M2,5	23.5	7.5	2.5	0.5
R3011.A-4	4	12	M2,5	23.5	7.5	2.5	0.5
R3011.A-5	5	12	M2,5	23.5	7.5	2.5	0.5
R3011.A-6	6	12	M2,5	23.5	7.5	2.5	0.5
R3011.B-4	4	16	M3	26.5	9	3	0.7
R3011.B-5	5	16	M3	26.5	9	3	0.7
R3011.B-6	6	16	M3	26.5	9	3	0.7
R3011.B-8	8	16	M3	26.5	9	3	0.7
R3011.C-5	5	20	M3	32	10	3.5	0.7
R3011.C-6	6	20	M3	32	10	3.5	0.7
R3011.C-8	8	20	M3	32	10	3.5	0.7
R3011.C-10	10	20	M3	32	10	3.5	0.7
R3011.D-6	6	25	M4	36.5	12	4.5	1.7
R3011.D-8	8	25	M4	36.5	12	4.5	1.7
R3011.D-10	10	25	M4	36.5	12	4.5	1.7
R3011.D-12	12	25	M4	36.5	12	4.5	1.7
R3011.E-6	6	32	M4	42	13.5	5.5	1.7
R3011.E-8	8	32	M4	42	13.5	5.5	1.7
R3011.E-10	10	32	M4	42	13.5	5.5	1.7
R3011.E-12	12	32	M4	42	13.5	5.5	1.7
R3011.E-14	14	32	M4	42	13.5	5.5	1.7