


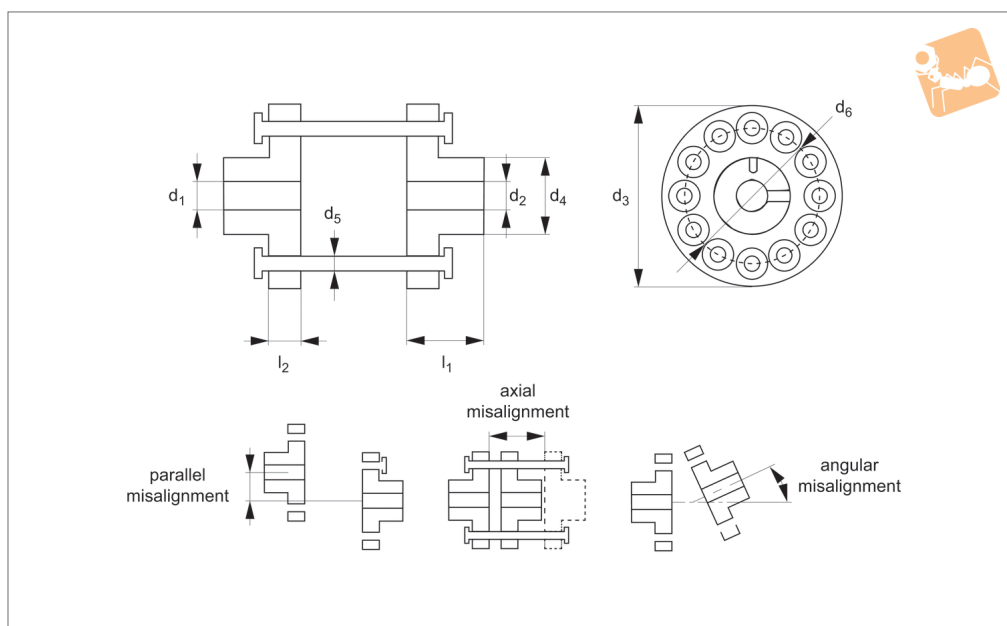

R3060

FLEXIBLE COUPLINGS

Material

Aluminium (DIN 3,1355) body with polyurethane connection shafts.

Technical Notes

Allows for very high levels of axial and

angular misalignment.

Type A - allows 10° of angular misalignment.

Type B - allows 30° of angular misalignment.

Order No.	d ₁ & d ₂ +0.5	d ₃	d ₄	d ₅	d ₆	l ₁	l ₂	Torque Ncm max.	Angle misalign. max.	No. of pins	Parallel misalign. mm max.	Axial misalign. mm max.
R3060.003-A	3	17.5	8.0	1.6	14.3	8.0	3.2	280	10°	8	1.6	3.6
R3060.005-A	5	25.5	9.5	3.2	19.1	8.7	3.2	390	10°	8	3.2	4.8
R3060.007-A	7	32.0	12.7	3.2	25.4	11.0	4.8	560	10°	10	6.4	6.4
R3060.008-A	8	38.0	12.7	4.8	28.6	11.0	4.8	680	10°	10	5.6	7.9
R3060.010-A	10	50.0	19.0	6.4	38.1	19.0	9.5	1130	10°	12	4.0	9.5
R3060.013-A	13	63.5	25.5	7.9	47.6	22.0	9.5	2260	10°	12	3.2	12.7
R3060.003-B	3	17.5	8.0	1.6	14.3	8.0	3.2	280	30°	8	12.7	11.0
R3060.005-B	5	25.5	9.5	3.2	19.1	8.7	3.2	390	30°	8	16.0	16.0
R3060.007-B	7	32.0	12.7	3.2	25.4	11.0	4.8	560	30°	10	19.0	22.0
R3060.008-B	8	38.0	12.7	4.8	28.6	11.0	4.8	680	30°	10	22.0	28.5
R3060.010-B	10	50.0	19.0	6.4	38.1	19.0	9.5	1130	30°	12	22.5	35.0
R3060.013-B	13	63.5	25.5	7.9	47.6	22.0	9.5	2260	30°	12	32.0	51.0

