


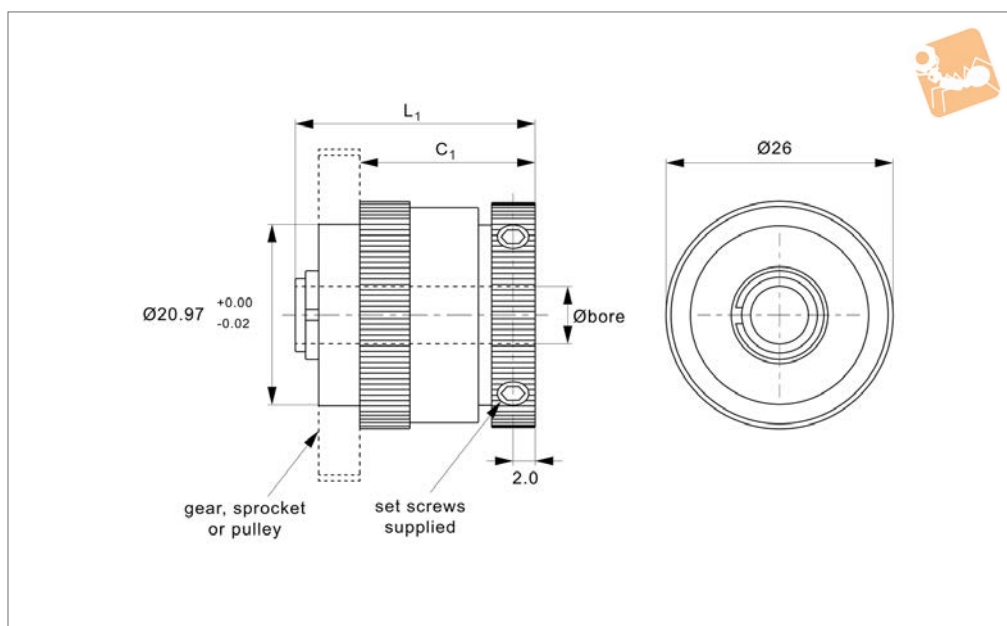

R3093

FLEXIBLE COUPLINGS

Material

Aluminium housing, adjuster ring and adapters.
Hub and plates - steel.

Sintered bronze bearing.

Technical Notes

Maximum backlash 2° , bi-directional.

Fine knurled torque adjustment rings.
Max. operating temperature 80°C .

Order No.	d_1 +0.03	l_1	l_2	Torque range Ncm min.	Torque range Ncm max.
R3093.006-020	6.00	26.4	20.0	2.5	53.5
R3093.008-020	8.00	26.4	20.0	2.5	53.5
R3093.006-026	6.00	32.4	25.6	7.8	132.0
R3093.008-026	8.00	32.4	25.6	7.8	132.0