


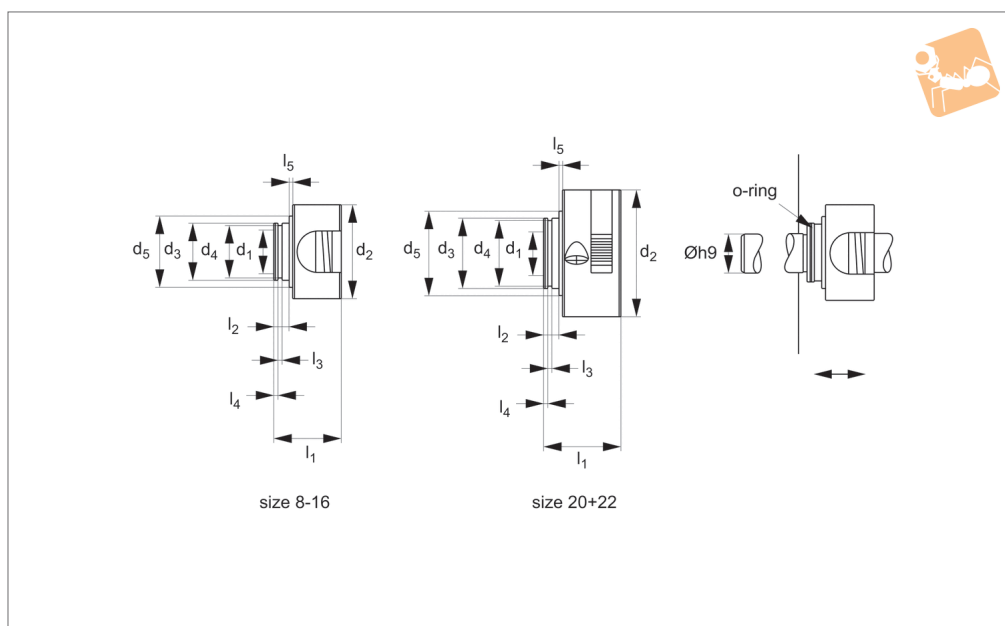

R3217

RIGID COUPLINGS

Material

Black thermoplastic body, other parts stainless steel. With NBR O ring.

Technical Notes

For positioning, clamping and quick

adjustment on shafts.

Clamping and mounting can be achieved using one hand in the pull direction.

Temperature range to 80C, F - axial holding force, one-sided.

Order No.	d ₁ tol. H7/H8	d ₂ tol. H7/H8	d ₃	d ₄	d ₅	l ₁	l ₂	l ₃	l ₄	l ₅	O-ring size	Axial force N max.	Weight g
R3217.080	8	40	25	22.4	31	27.5	7	1.7	3.15	0.5	22x1,5	250	31
R3217.100	10	40	25	22.4	31	27.5	7	1.7	3.15	0.5	22x1,5	250	30
R3217.120	12	40	25	22.4	31	27.5	7	1.7	3.15	0.5	22x1,5	350	30
R3217.150	15	40	25	22.4	31	27.5	7	1.7	3.15	0.5	22x1,5	350	28
R3217.160	16	40	25	22.4	31	27.5	7	1.7	3.15	0.5	22x1,5	380	27
R3217.200	20	55	30	27.4	37	32.5	7	1.7	2.65	0.5	27x1,5	320	51
R3217.220	22	55	30	27.4	37	32.5	7	1.7	2.65	0.5	27x1,5	320	50

