




Clevis Pin With Thread

To DIN 1445. 303 stainless steel

Clevis Joints & Clips

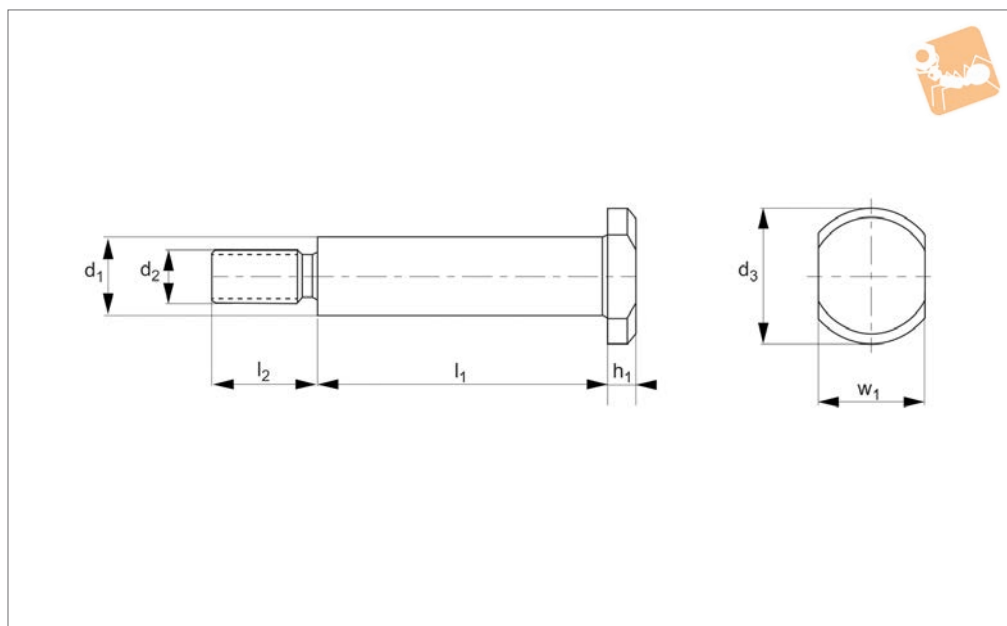

R3428

CLEVIS JOINTS & CLIPS

Material

AISI 303 Stainless Steel (1.4305)

Technical Notes

Designed for use with clevis joints. $l_1 + l_2$ tol.js15 To DIN 1445.

Tips

For use with clevis joints R3402 and R3403. For washers see part number P0330.A2.

Order No.	d_1 h11	d_2	d_3 h13	h_1 js14	l_1	l_2	w_1
R3428.080-016-A2	8	M6	14	3.0	16	11	11
R3428.080-020-A2	8	M6	14	3.0	20	11	11
R3428.080-025-A2	8	M6	14	3.0	25	11	11
R3428.080-030-A2	8	M6	14	3.0	30	11	11
R3428.100-020-A2	10	M8	18	4.0	20	14	13
R3428.100-025-A2	10	M8	18	4.0	25	14	13
R3428.100-030-A2	10	M8	18	4.0	30	14	13
R3428.100-035-A2	10	M8	18	4.0	35	14	13
R3428.120-024-A2	12	M10	20	4.0	24	17	17
R3428.120-030-A2	12	M10	20	4.0	30	17	17
R3428.120-035-A2	12	M10	20	4.0	35	17	17
R3428.120-040-A2	12	M10	20	4.0	40	17	17
R3428.140-027-A2	14	M12	22	4.0	27	20	19
R3428.140-030-A2	14	M12	22	4.0	30	20	19
R3428.140-035-A2	14	M12	22	4.0	35	20	19
R3428.140-040-A2	14	M12	22	4.0	40	20	19
R3428.160-032-A2	16	M12	25	4.5	32	20	22
R3428.160-035-A2	16	M12	25	4.5	35	20	22
R3428.160-040-A2	16	M12	25	4.5	40	20	22
R3428.160-045-A2	16	M12	25	4.5	45	20	22