




Ball Joint - Housing Only

Ball & Socket Joints

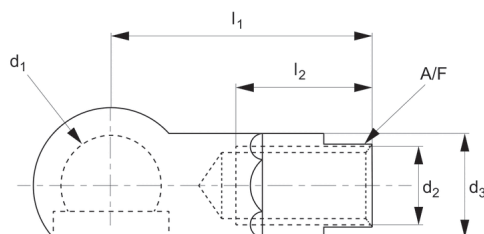

R3524

BALL & SOCKET JOINTS

Material

Low carbon steel, silver zinc plated.

Technical Notes

To DIN 71802.

Tips

Standard thread is right hand thread.

Important Notes

These ball joints are used in light linkage applications where it is desired to have the ability to be able to remove the ball stud.

The ball joint is supplied WITHOUT the ball stud and retaining clip.

Order No.	Thread hand	d ₁	d ₂	l ₁	l ₂	d ₃	A/F
R3524.R005	Right	8	M 5	22	10.2	8	7
R3524.R006	Right	10	M 6	25	11.5	10	9
R3524.R008	Right	13	M 8	30	14.0	13	11
R3524.R010	Right	16	M10	35	15.5	16	13
R3524.R012	Right	16	M12	35	15.5	16	13

