


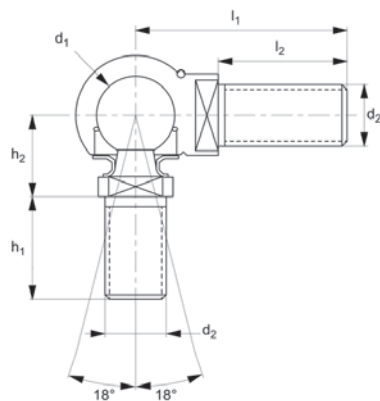

R3538

Material

Low carbon steel, silver zinc plated.

stud in the housing.

Technical Notes

Safety ring aids the retention of the ball

Tips

Standard thread is right hand thread.

Order No.	Thread hand	d ₁	d ₂	l ₁	l ₂	h ₁	h ₂
R3538.R005	Right	8	M 5	22.5	12.0	10.2	9
R3538.R006	Right	10	M 6	25.0	13.5	12.5	11
R3538.R008	Right	13	M 8	31.5	17.5	16.5	13
R3538.R010	Right	16	M10	37.5	21.5	20.0	16
R3538.R012	Right	16	M12	42.0	25.5	20.0	16
R3538.L005	Left	8	M 5	22.5	12.0	10.2	9
R3538.L006	Left	10	M 6	25.0	13.5	12.5	11
R3538.L008	Left	13	M 8	31.5	17.5	16.5	13
R3538.L010	Left	16	M10	37.5	21.5	20.0	16
R3538.L012	Left	16	M12	42.0	25.5	20.0	16