



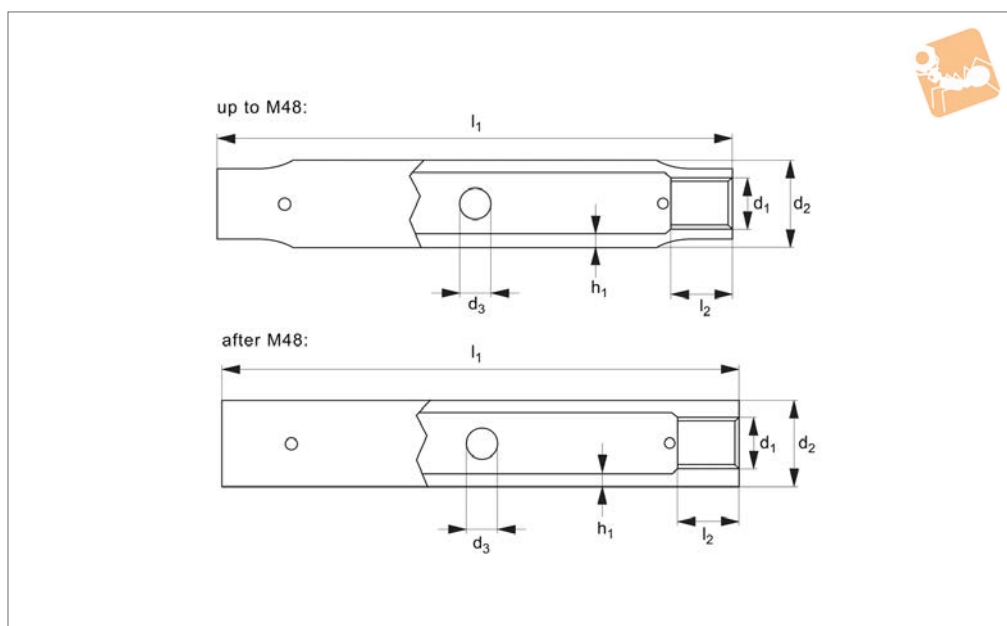

Pipe Body Turnbuckles

steel

Turnbuckles

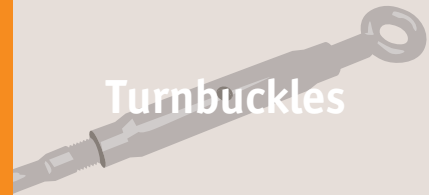

R3800

TURNBUCKLES

Material

Steel (1.0037), zinc-plated.
Hot dip galvanized, available on request
providing increased protection against
corrosion. Please add -FZ for hot dip galva-
nized, e.g. R3800.006-FZ.

Tips

Turnbuckles consist of a metal frame with
right hand thread one end and left hand
thread the other end. Used for tensioning
by rotating turnbuckle body without twis-
ting attached rope or cable.

Only suitable for use in tension.

Technical Notes

To DIN 1478.

Important Notes

Turnbuckles are not to be used for lifting.

Order No.	d ₁	l ₁	d ₂	d ₃ min.	d ₃ max.	h ₁	l ₂	Adjustment	Weight kg
R3800.006-ZP	M 6	110	17.2	5.7	6.3	2.9	7.5	90	0.13
R3800.008-ZP	M 8	110	17.2	7.5	8.5	3.6	10	85	0.13
R3800.010-ZP	M10	125	21.3	7.5	8.5	4.0	12	95	0.18
R3800.012-ZP	M12	125	25.0	9.5	10.5	4.0	15	90	0.25
R3800.016-ZP	M16	170	30.0	9.5	10.5	4.5	20	120	0.45
R3800.020-ZP	M20	200	33.7	11.5	12.5	5.0	24	140	0.56
R3800.024-ZP	M24	255	42.4	11.5	12.5	5.6	29	180	1.08
R3800.030-ZP	M30	255	51.0	15.5	16.5	6.3	36	160	1.61
R3800.036-ZP	M36	295	63.5	15.5	16.5	8.0	43	180	2.35
R3800.042-ZP	M42	330	70.0	19.5	20.5	8.8	51	200	4.30
R3800.048-ZP	M48	355	82.5	19.5	20.5	10.0	58	210	5.50
R3800.056-ZP	M56	355	90.0	24.5	25.5	15.0	68	190	9.60
R3800.064-ZP	M64	425	100	24.5	25.5	16	77	240	14.00
R3800.072-ZP	M72x6	425	110	29.5	30.5	17	87	210	17.00
R3800.080-ZP	M80x6	440	120	29.5	30.5	18	96	210	21.00