



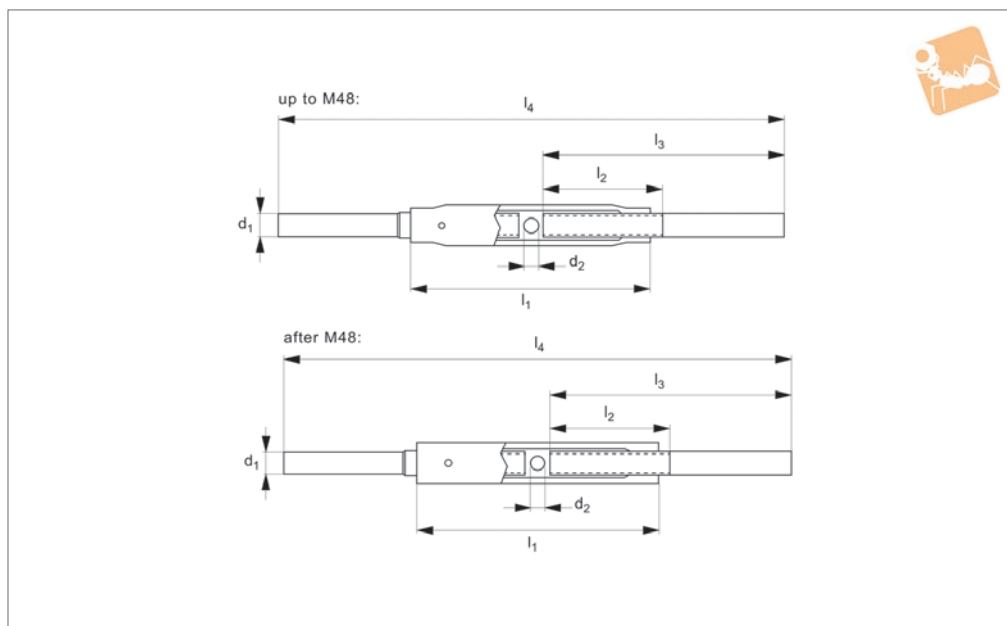

Stud End Pipe Body Turnbuckles

steel

Turnbuckles

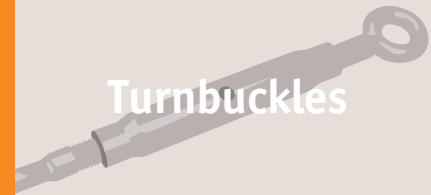

R3804

TURNBUCKLES

Material

Steel (1.0037 up to M48 then 1.0052), zinc-plated.
Hot dip galvanized, available on request providing increased protection against corrosion. Please add -FZ for hot dip galvanized, e.g. R3804.006-FZ.

Technical Notes

To DIN 1478.

Tips

Turnbuckles consist of a metal frame with right hand thread one end and left hand thread the other end. Used for tensioning

by rotating turnbuckle body without twisting attached rope or cable.

Important Notes

Turnbuckles are not to be used for lifting.
Only suitable for use in tension.

Order No.	d ₁	l ₁	d ₂	l ₂	l ₃	l ₄ min.	l ₄ max.	Weight kg
R3804.006-ZP	M 6	110	6	60	120	246	336	0.17
R3804.008-ZP	M 8	110	8	65	120	248	333	0.20
R3804.010-ZP	M10	125	8	75	150	309	404	0.32
R3804.012-ZP	M12	125	10	75	150	311	401	0.45
R3804.016-ZP	M16	170	10	100	200	410	530	0.97
R3804.020-ZP	M20	200	12	120	220	452	592	1.48
R3804.024-ZP	M24	255	12	150	260	533	713	2.62
R3804.030-ZP	M30	255	16	160	260	537	697	4.01
R3804.036-ZP	M36	295	16	180	300	617	797	6.35
R3804.042-ZP	M42	330	20	200	350	720	920	10.50
R3804.048-ZP	M48	355	20	220	380	781	991	14.30
R3804.056-ZP	M56	355	25	230	380	785	975	21.60
R3804.064-ZP	M64	425	25	300	425	875	1015	32.40
R3804.072-ZP	M72	425	30	270	400	831	1041	42.00
R3804.080-ZP	M80	440	30	270	400	830	1040	51.00

