



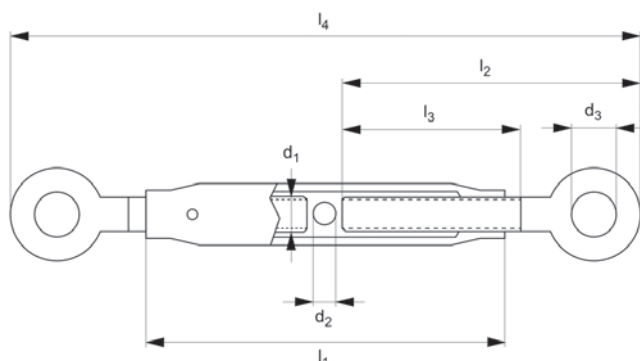

Eye End Pipe Body Turnbuckles

steel

Turnbuckles

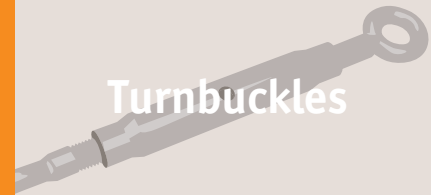

R3808

TURNBUCKLES

Material

Steel (1.0037), zinc-plated.
Hot dip galvanized, available on request providing increased protection against corrosion. Please add -FZ for hot dip galvanized, e.g. R3804.006-FZ.

Tips

Turnbuckles consist of a metal frame with right hand thread one end and left hand thread the other end. Used for tensioning by rotating turnbuckle body without twisting attached rope or cable.

Only suitable for use in tension.

Technical Notes

To DIN 1478.

Important Notes

Turnbuckles are not to be used for lifting.

Order No.	d ₁	l ₁	d ₂	d ₃	l ₂	l ₃	l ₄ min.	l ₄ max	Weight kg
R3808.006-ZP	M 6	110	6	10	74	50	154	244	0.16
R3808.008-ZP	M 8	110	8	11	80	52	168	253	0.18
R3808.010-ZP	M10	125	8	15	95	59	199	294	0.28
R3808.012-ZP	M12	125	10	17	107	66	225	315	0.42
R3808.016-ZP	M16	170	10	22	146	85	302	422	0.91
R3808.020-ZP	M20	200	12	24	170	100	352	492	1.36
R3808.024-ZP	M24	255	12	33	213	134	437	619	2.60
R3808.030-ZP	M30	255	16	39	255	150	527	687	3.75
R3808.036-ZP	M36	295	16	37	260	150	537	717	6.35
R3808.042-ZP	M42	330	20	48	285	165	590	790	10.50
R3808.048-ZP	M48	355	20	58	335	185	691	901	15.50