



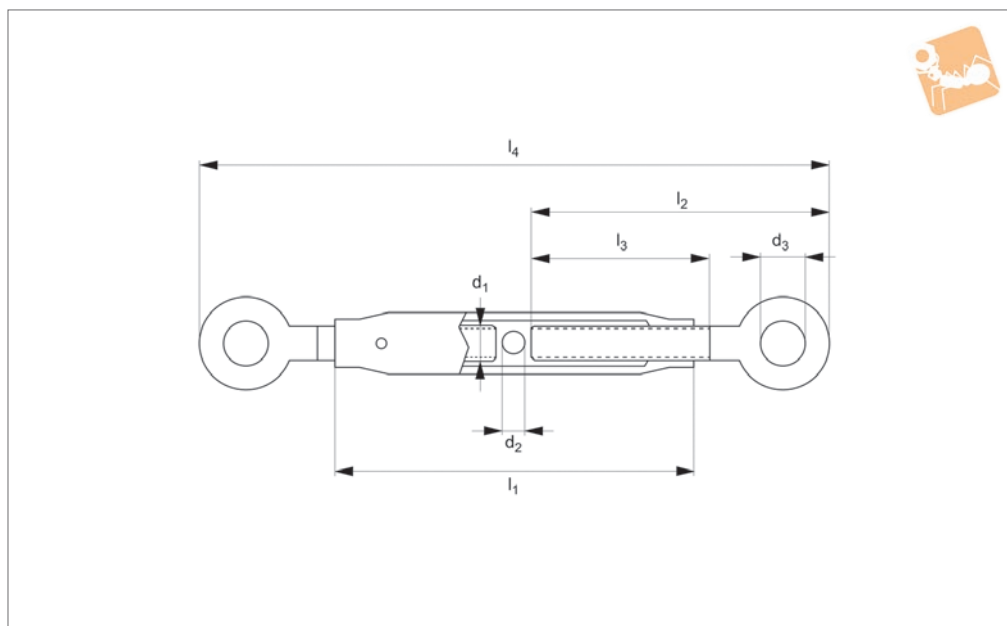

Eye End Pipe Body Turnbuckles

stainless steel

Turnbuckles

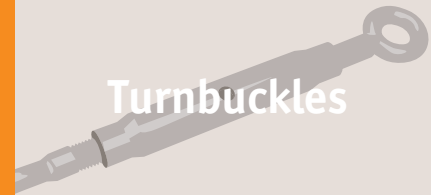

R3810

TURNBUCKLES

Material

Stainless steel (A4)

Technical Notes

To DIN 1478.

Tips

Turnbuckles consist of a metal frame with

right hand thread one end and left hand thread the other end. Used for tensioning by rotating turnbuckle body without twisting attached rope or cable.

Only suitable for use in tension.

Important Notes

Turnbuckles are not to be used for lifting.

Order No.	d ₁	d ₂	d ₃	l ₁	l ₂	l ₃	l ₄ min.	l ₄ max.	Weight kg
R3810.006-A4	M 6	6	10	110	74	50	154	244	0.16
R3810.008-A4	M 8	8	11	110	80	52	168	253	0.18
R3810.010-A4	M10	8	15	125	95	59	199	294	0.28
R3810.012-A4	M12	10	17	125	107	66	225	315	0.42
R3810.016-A4	M16	10	22	170	146	85	302	422	0.91
R3810.020-A4	M20	12	24	200	170	100	352	492	1.36