

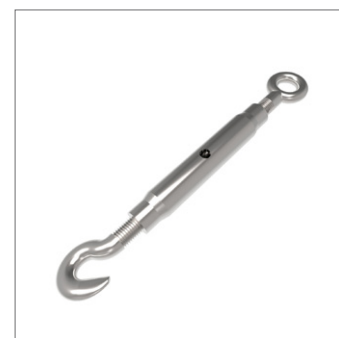


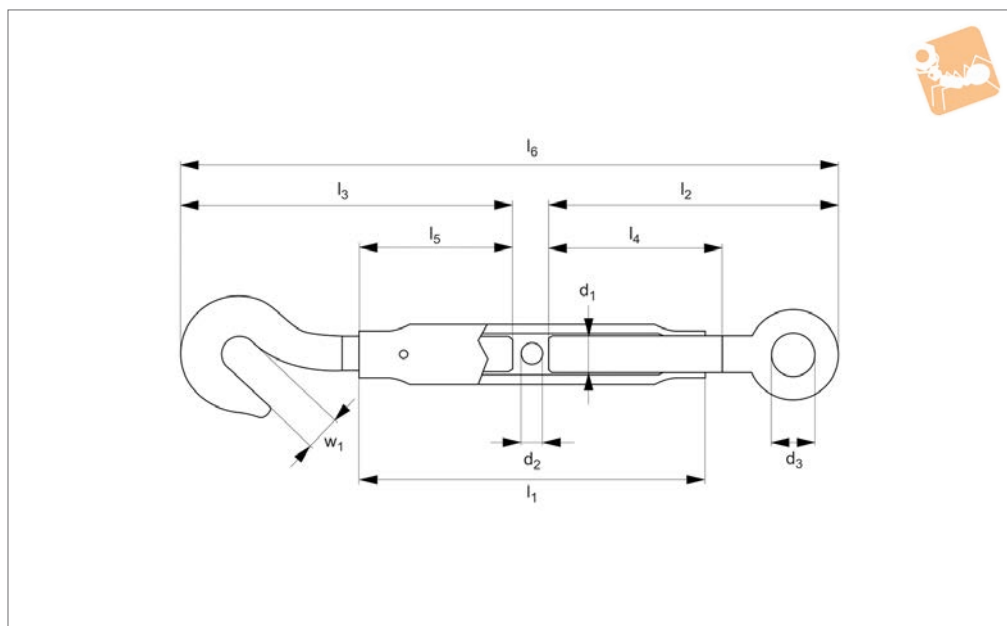

Hook & Eye Pipe Body Turnbuckles

steel

Turnbuckles

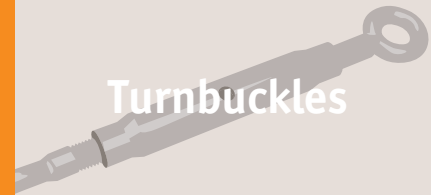

R3812

TURNBUCKLES

Material

Steel (1.0037 up to M48 then 1.0052), zinc-plated.
Hot dip galvanized body, available on request providing increased protection against corrosion. Please add -FZ for hot dip galvanized, e.g. R3804.006-FZ.

Technical Notes

To DIN 1478.

Tips

Turnbuckles consist of a metal frame with right hand thread one end and left hand thread the other end. Used for tensioning

by rotating turnbuckle body without twisting attached rope or cable.

Important Notes

Turnbuckles are not to be used for lifting. Only suitable for use in tension.

Order No.	d ₁	l ₁	d ₂	d ₃	l ₂	l ₃	l ₄	l ₅	l ₆ min.	l ₆ max.	w ₁	Weight kg
R3812.006-ZP	M 6	110	6	10	74	77.0	50	50	157	247	9.5	0.16
R3812.008-ZP	M 8	110	8	11	80	98.0	52	60	186	271	11.0	0.19
R3812.010-ZP	M10	125	8	15	95	116.5	59	73	220	315	14.0	0.29
R3812.012-ZP	M12	125	10	17	107	146.0	66	90	264	354	18.0	0.45
R3812.016-ZP	M16	170	10	22	146	165.0	85	100	321	441	19.0	0.96
R3812.020-ZP	M20	200	12	24	170	180.0	100	105	362	502	21.0	1.38
R3812.024-ZP	M24	255	12	33	213	225.0	134	135	450	630	29.0	2.73
R3812.030-ZP	M30	255	16	39	255	255.0	150	140	527	687	31.0	3.92
R3812.036-ZP	M36	295	16	37	260	300.0	150	170	577	757	35.0	6.60