

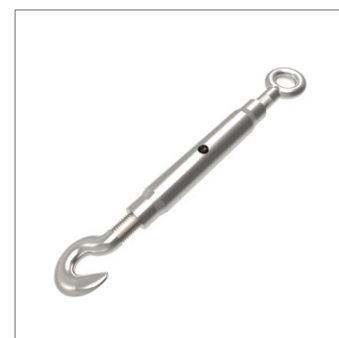


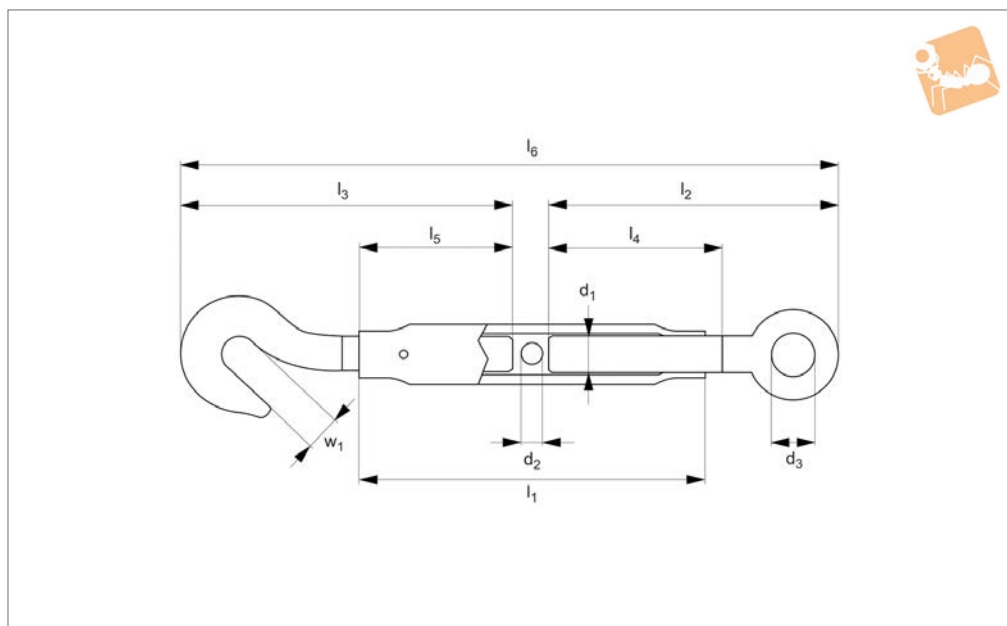

Hook & Eye Pipe Body Turnbuckles

stainless steel

Turnbuckles

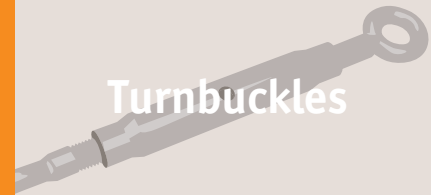

R3814

TURNBUCKLES

Material

Stainless steel (A4)

Technical Notes

To DIN 1478.

Tips

Turnbuckles consist of a metal frame with

right hand thread one end and left hand thread the other end. Used for tensioning by rotating turnbuckle body without twisting attached rope or cable.

Only suitable for use in tension.

Important Notes

Turnbuckles are not to be used for lifting.

Order No.	d ₁	d ₂	d ₃	l ₁	l ₂	l ₃	l ₄	l ₅	l ₆ min.	l ₆ max.	w ₁	Weight kg
R3814.006-A4	M 6	6	10	110	74	77.0	50	50	157	247	9.5	0.16
R3814.008-A4	M 8	8	11	110	80	98.0	52	60	186	271	11.0	0.19
R3814.010-A4	M10	8	15	125	95	116.5	59	73	220	315	14.0	0.29
R3814.012-A4	M12	10	17	125	107	146.0	66	90	264	354	18.0	0.45
R3814.016-A4	M16	10	22	170	146	165.0	85	100	321	441	19.0	0.96