



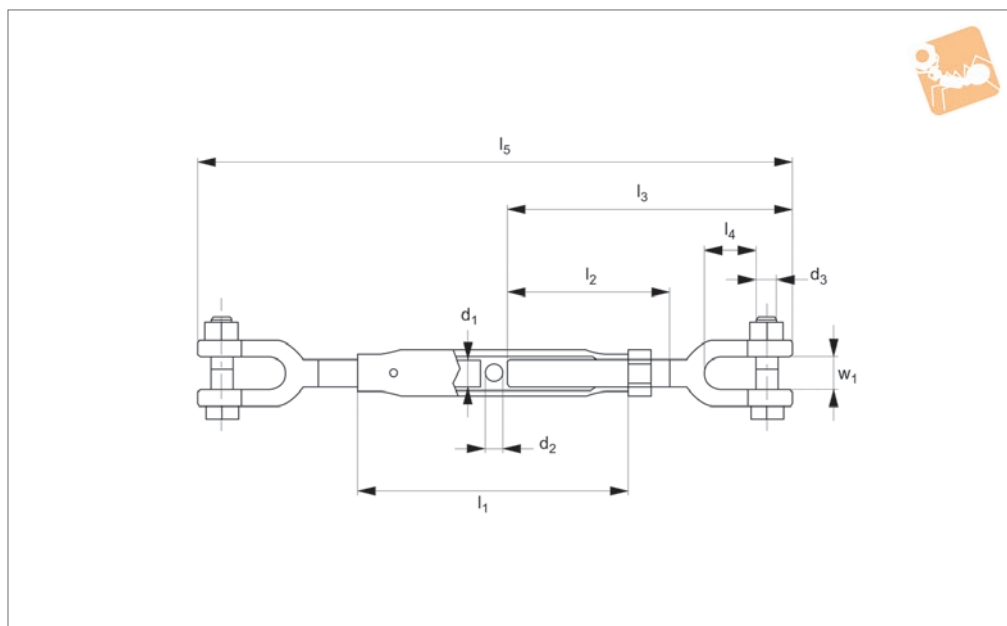

Jaw End Pipe Body Turnbuckles

steel

Turnbuckles

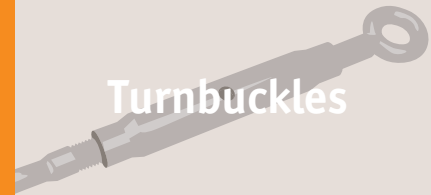

R3820

TURNBUCKLES

Material

Steel body(1.0037) Jaws (1.0503), zinc-plated.

Hot dip galvanized body, available on request providing increased protection against corrosion. Please add -FZ for hot dip galvanized, e.g. R3804.006-FZ.

Technical Notes

To DIN 1478.

Tips

Turnbuckles consist of a metal frame with right hand thread one end and left hand thread the other end. Used for tensioning

by rotating turnbuckle body without twisting attached rope or cable.

Important Notes

Turnbuckles are not to be used for lifting. Only suitable for use in tension.

Order No.	d ₁	l ₁	d ₂	d ₃	l ₂	l ₃	l ₄	l ₅ min.	l ₅ max.	w ₁	Weight kg
R3820.008-ZP	M 8	110	8.5	8.5	68	125	28.75	258	343	9.0	0.30
R3820.010-ZP	M10	125	8.5	8.5	82	139	29.25	287	382	10.7	0.43
R3820.012-ZP	M12	125	10.5	10.5	90	160	44.75	331	421	15.5	0.69
R3820.016-ZP	M16	170	10.5	12.5	102	186	45.25	382	502	20.0	1.31
R3820.020-ZP	M20	200	12.5	17.0	115	205	59.5	422	562	23.5	2.02
R3820.024-ZP	M24	255	12.5	20.5	125	240	62.75	493	673	26.0	3.9
R3820.030-ZP	M30	255	16.5	25.0	150	290	89.5	613	773	34.0	7.01