



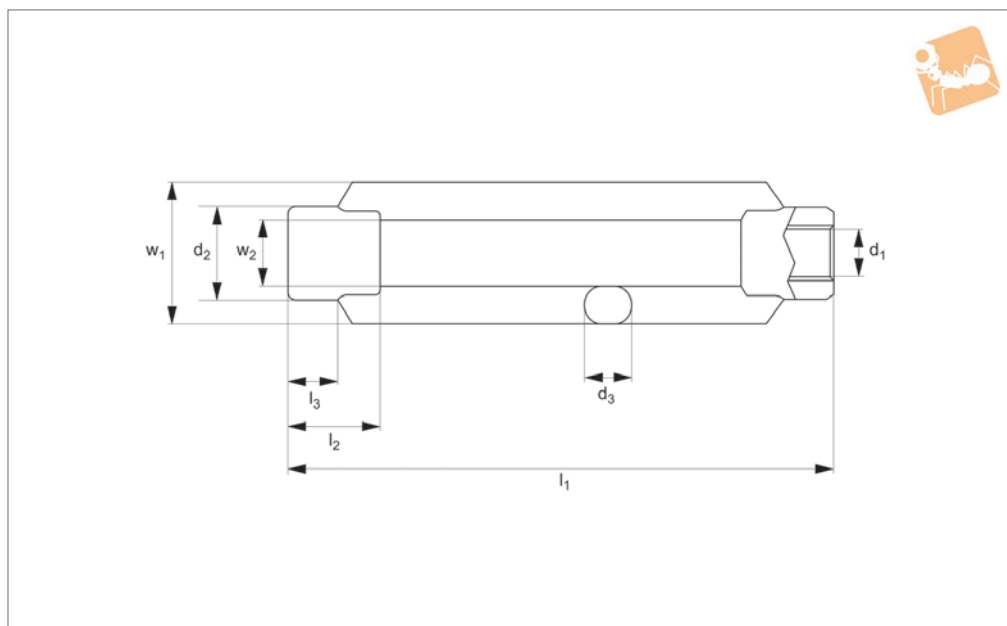

# Turnbuckles steel

## Turnbuckles

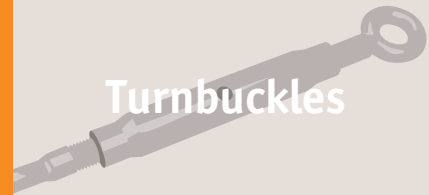

**R3830**

TURNBUCKLES

### Material

Steel (1.0037), zinc-plated.  
Hot dip galvanized, available on request  
providing increased protection against  
corrosion.

### Technical Notes

To DIN 1480.

### Tips

Turnbuckles consist of a metal frame with  
right hand thread one end and left hand  
thread the other end. Used for tensioning  
by rotating turnbuckle body without twist-  
ing attached rope or cable.

### Important Notes

**Turnbuckles are not to be used for lifting.  
Only suitable for use in tension.**

| Order No.    | d <sub>1</sub> | l <sub>1</sub> | l <sub>2</sub> | l <sub>3</sub> | d <sub>2</sub> | d <sub>3</sub> | w <sub>1</sub> | w <sub>2</sub> | Adjustment | Weight<br>kg |
|--------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|------------|--------------|
| R3830.006-ZP | M 6            | 110            | 12             | 6              | 12             | 6              | 19             | 9              | 80         | 0.06         |
| R3830.008-ZP | M 8            | 110            | 15             | 8              | 15             | 8              | 23             | 11             | 75         | 0.09         |
| R3830.010-ZP | M10            | 125            | 18             | 9              | 18             | 9              | 30             | 14             | 85         | 0.15         |
| R3830.012-ZP | M12            | 125            | 21             | 11             | 21             | 11             | 34             | 16             | 80         | 0.20         |
| R3830.016-ZP | M16            | 170            | 27             | 14             | 27             | 14             | 42             | 20             | 110        | 0.44         |
| R3830.020-ZP | M20            | 200            | 34             | 17             | 34             | 17             | 52             | 24             | 130        | 0.44         |
| R3830.024-ZP | M24            | 255            | 39             | 20             | 39             | 20             | 60             | 28             | 170        | 1.20         |
| R3830.030-ZP | M30            | 255            | 45             | 23             | 45             | 23             | 74             | 34             | 160        | 1.80         |
| R3830.036-ZP | M36            | 295            | 55             | 28             | 55             | 28             | 86             | 40             | 180        | 3.20         |
| R3830.042-ZP | M42            | 330            | 63             | 32             | 63             | 32             | 104            | 50             | 200        | 4.50         |
| R3830.048-ZP | M48            | 355            | 78             | 39             | 80             | 40             | 135            | 65             | 195        | 9.10         |
| R3830.056-ZP | M56            | 355            | 78             | 39             | 80             | 40             | 135            | 65             | 195        | 8.00         |