



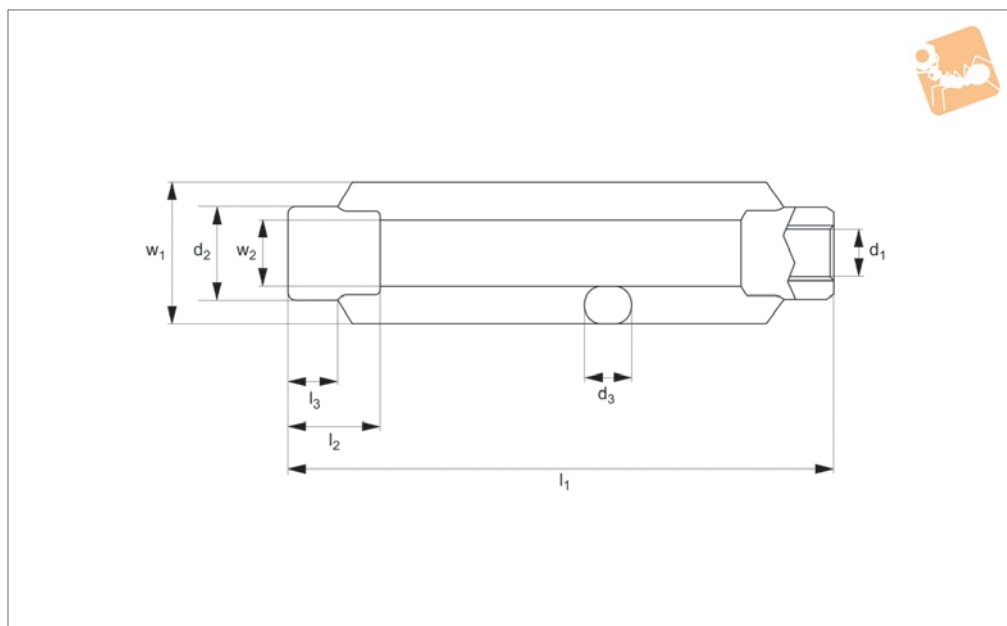

Turnbuckles stainless steel

Turnbuckles

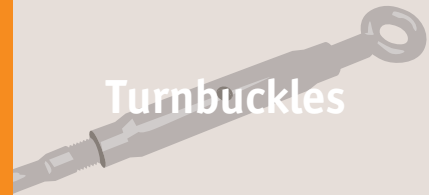

R3832

TURNBUCKLES

Material

Stainless steel (A4).

Technical Notes

To DIN 1480.

Tips

Turnbuckles consist of a metal frame with

right hand thread one end and left hand thread the other end. Used for tensioning by rotating turnbuckle body without twisting attached rope or cable.

Only suitable for use in tension.

Important Notes

Turnbuckles are not to be used for lifting.

Order No.	d ₁	d ₂	d ₃	l ₁	l ₂	l ₃	w ₁	w ₂	Adjustment	Weight kg
R3832.050-070-A4	M 5	-	-	70	-	-	-	-	-	-
R3832.060-110-A4	M 6	12	6	110	12	6	19	9	80	0.06
R3832.060-090-A4	M 6	8	6	90	12	6	19	9	80	0.06
R3832.080-110-A4	M 8	15	8	110	15	8	23	11	75	0.09
R3832.100-125-A4	M10	18	9	125	18	9	30	14	85	0.15
R3832.100-150-A4	M10	16	9	150	18	9	30	14	85	0.15
R3832.120-125-A4	M12	21	11	125	21	11	34	16	80	0.20
R3832.120-200-A4	M12	18	11	200	21	11	34	16	80	0.20
R3832.160-170-A4	M16	27	14	170	27	14	42	20	110	0.44
R3832.160-250-A4	M16	26	14	250	27	14	42	20	110	0.44
R3832.200-200-A4	M20	34	17	200	34	17	52	24	130	0.44
R3832.200-300-A4	M20	30	17	300	34	17	52	24	130	0.44
R3832.240-255-A4	M24	39	20	255	39	20	60	28	170	1.20

