



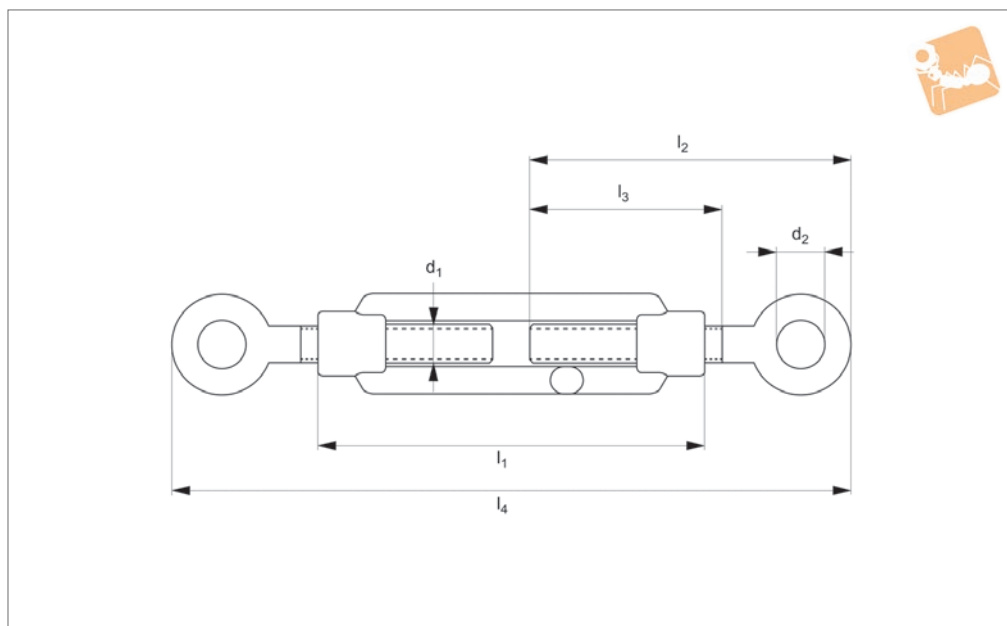

Eye End Turnbuckles

stainless steel

Turnbuckles

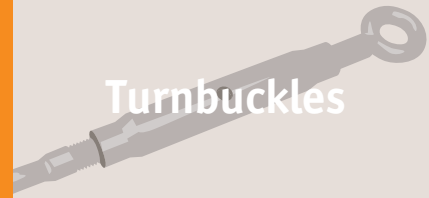

R3842

TURNBUCKLES

Material

Stainless steel (A4).

Technical Notes

To DIN 1480 eye to eye.

Tips

Turnbuckles consist of a metal frame with

right hand thread one end and left hand thread the other end. Used for tensioning by rotating turnbuckle body without twisting attached rope or cable.

Only suitable for use in tension.

Important Notes

Turnbuckles are not to be used for lifting.

Order No.	d ₁	d ₂	l ₁	l ₂	l ₃	l ₄ min.	l ₄ max.	Weight kg
R3842.006-A4	M 6	10	110	74	50	148	228	0.09
R3842.008-A4	M 8	11	110	80	52	160	235	0.14
R3842.010-A4	M10	15	125	95	59	191	276	0.25
R3842.012-A4	M12	17	125	107	66	215	295	0.37
R3842.016-A4	M16	22	170	146	85	292	402	0.90
R3842.020-A4	M20	24	200	170	100	340	470	1.62