



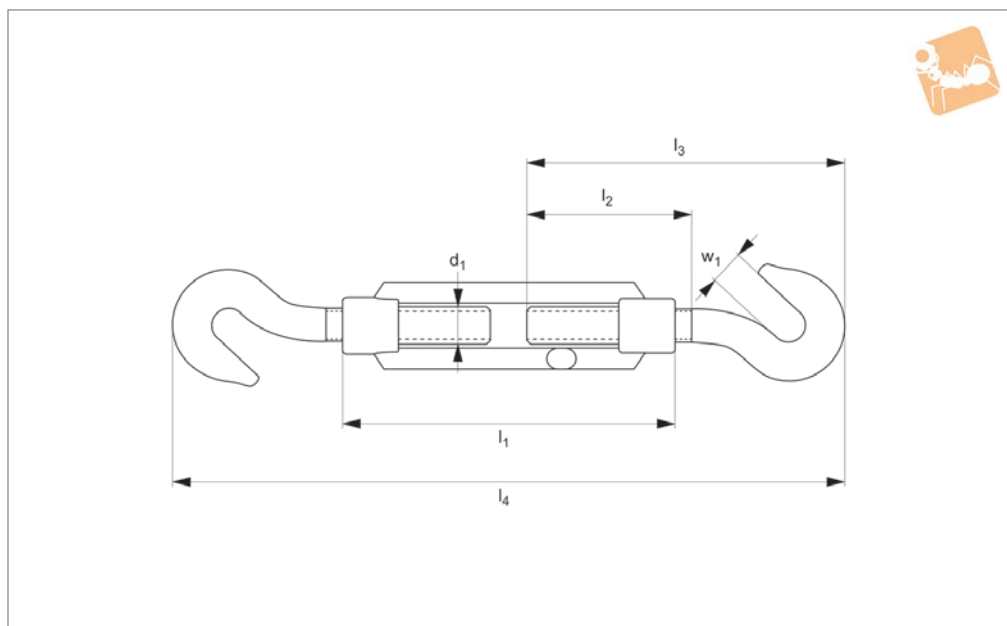

Hook End Turnbuckles

steel

Turnbuckles

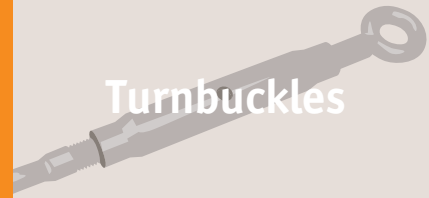

R3844

TURNBUCKLES

Material

Steel (1.0037), zinc-plated.
Hot dip galvanized body, available on request providing increased protection against corrosion. Please add -FZ for hot dip galvanized, e.g. R3804.006-FZ.

Tips

Turnbuckles consist of a metal frame with right hand thread one end and left hand thread the other end. Used for tensioning by rotating turnbuckle body without twisting attached rope or cable.

Only suitable for use in tension.

Technical Notes

To DIN 1480 hook to hook.

Important Notes

Turnbuckles are not to be used for lifting.

Order No.	d ₁	l ₁	l ₂	l ₃	l ₄ min.	l ₄ max.	w ₁	Weight kg
R3844.006-ZP	M 6	110	50	77.0	154	234	8.0	0.09
R3844.008-ZP	M 8	110	60	98.0	196	271	10.0	0.16
R3844.010-ZP	M10	125	73	116.5	233	318	12.5	0.27
R3844.012-ZP	M12	125	90	146.0	293	373	16.0	0.42
R3844.016-ZP	M16	170	100	165.0	330	440	16.0	1.00
R3844.020-ZP	M20	200	105	180.0	360	490	18.0	1.66
R3844.024-ZP	M24	255	135	225.0	451	621	30.0	2.98
R3844.030-ZP	M30	255	140	255.0	451	611	30.0	4.28
R3844.036-ZP	M36	295	170	300.0	601	781	32.0	7.70