



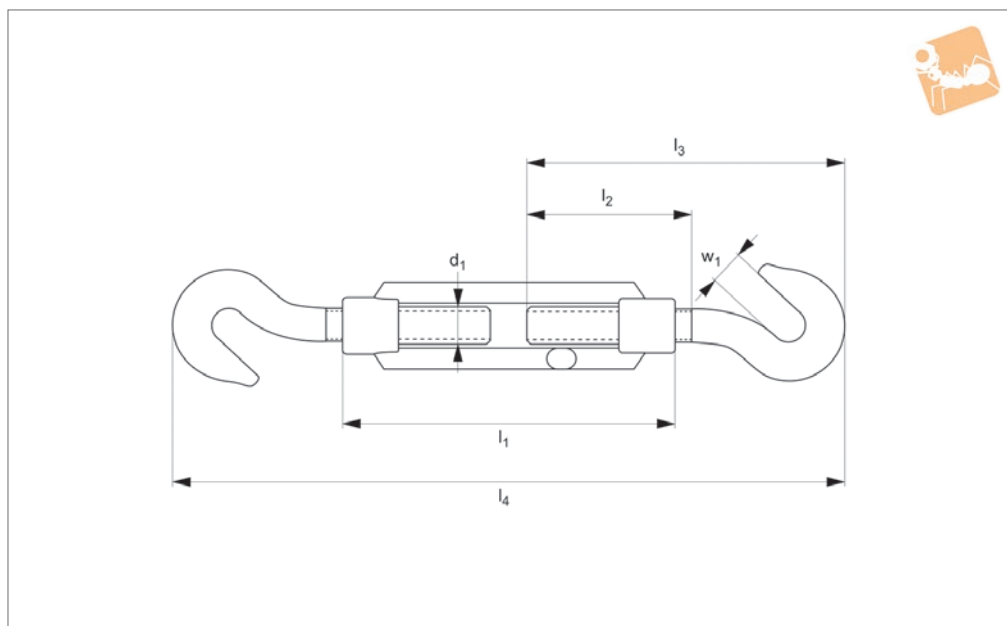

Hook End Turnbuckles

stainless steel

Turnbuckles

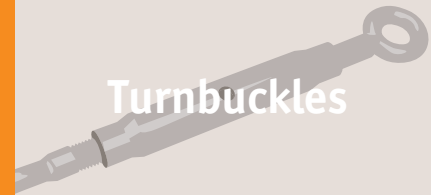

R3846

TURNBUCKLES

Material

Stainless steel (A4).

Technical Notes

To DIN 1480 hook to hook.

Tips

Turnbuckles consist of a metal frame with

right hand thread one end and left hand thread the other end. Used for tensioning by rotating turnbuckle body without twisting attached rope or cable.

Only suitable for use in tension.

Important Notes

Turnbuckles are not to be used for lifting.

Order No.	d ₁	l ₁	l ₂	l ₃	l ₄ min.	l ₄ max.	w ₁	Weight kg
R3846.006-A4	M 6	110	50	77.0	154	234	8.0	0.09
R3846.008-A4	M 8	110	60	98.0	196	271	10.0	0.16
R3846.010-A4	M10	125	73	116.5	233	318	12.5	0.27
R3846.012-A4	M12	125	90	146.0	293	373	16.0	0.42
R3846.016-A4	M16	170	100	165.0	330	440	16.0	1.00