



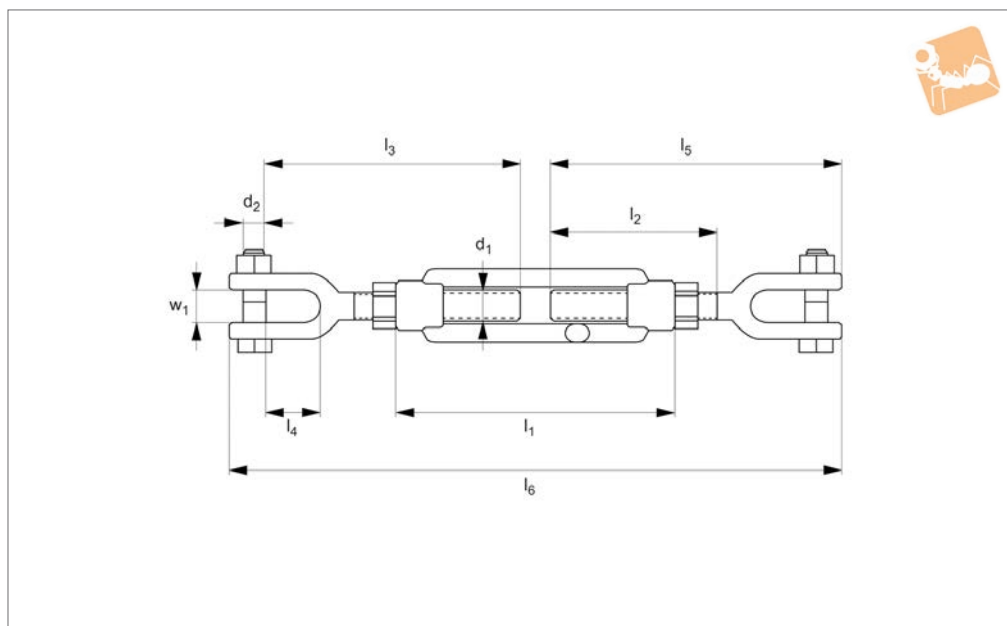

Jaw End Turnbuckle steel

Turnbuckles

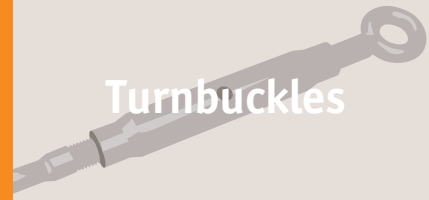

R3848

TURNBUCKLES

Material

Steel body (1.0037), jaws (1.0503), zinc-plated.

Hot dip galvanized body, available on request providing increased protection against corrosion. Please add -FZ for hot dip galvanized, e.g. R3804.006-FZ.

Technical Notes

To DIN 1480 jaw to jaw.

Tips

Turnbuckles consist of a metal frame with right hand thread one end and left hand thread the other end. Used for tensioning

by rotating turnbuckle body without twisting attached rope or cable.

Important Notes

Turnbuckles are not to be used for lifting. Only suitable for use in tension.

Order No.	d ₁	l ₁	l ₂	l ₃	l ₄	d ₂	l ₅	l ₆ min.	l ₆ max.	w	Weight kg
R3848.008-ZP	M 8	110	68	116	28.75	8.5	125	250	325	9.0	0.14
R3848.010-ZP	M10	125	82	130	29.25	8.5	139	279	364	10.7	0.26
R3848.012-ZP	M12	125	90	150	44.75	10.5	160	321	401	15.5	0.40
R3848.016-ZP	M16	170	102	172	45.25	12.5	186	372	482	20.0	0.64
R3848.020-ZP	M20	200	115	185	59.50	17.5	205	410	540	23.5	1.30
R3848.024-ZP	M24	255	125	215	62.75	20.5	240	481	651	29.0	2.28
R3848.030-ZP	M30	255	150	255	89.50	25.5	290	581	741	34.0	4.02