



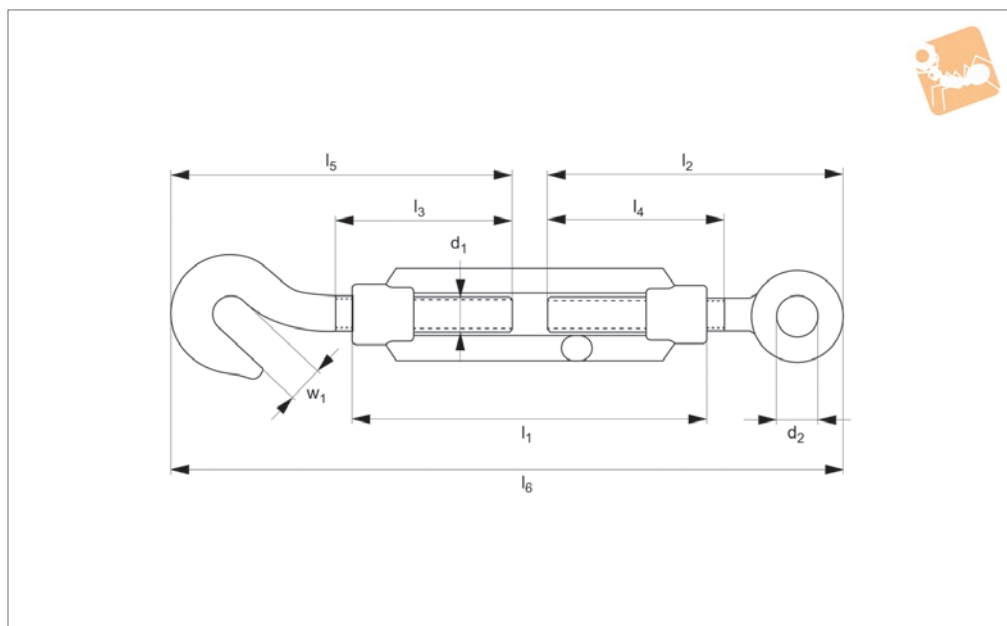

Hook & Eye Turnbuckles

stainless steel

Turnbuckles

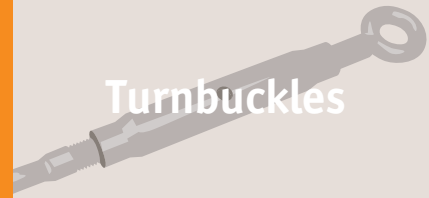

R3852

TURNBUCKLES

Material

Stainless steel (A4).

Technical Notes

To DIN 1480 hook & eye.

Tips

Turnbuckles consist of a metal frame with

right hand thread one end and left hand thread the other end. Used for tensioning by rotating turnbuckle body without twisting attached rope or cable.

Only suitable for use in tension.

Important Notes

Turnbuckles are not to be used for lifting.

Order No.	d ₁	d ₂	l ₁	l ₂	l ₃	l ₄	l ₅	l ₆ min.	w ₁	Weight kg
R3852.006-A4	M 6	10	110	74	50	50	77.0	151	8.0	0.09
R3852.008-A4	M 8	11	110	80	52	60	98.0	178	10.0	0.15
R3852.010-A4	M10	15	125	95	59	73	116.5	212	12.5	0.26
R3852.012-A4	M12	17	125	107	66	90	146.0	264	16.0	0.40
R3852.016-A4	M16	22	170	146	85	100	165.0	311	16.0	0.95