

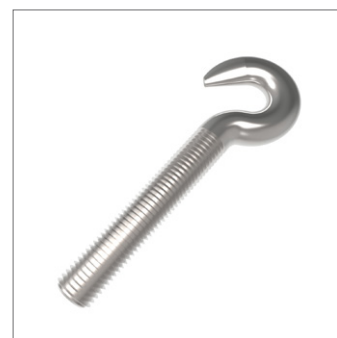


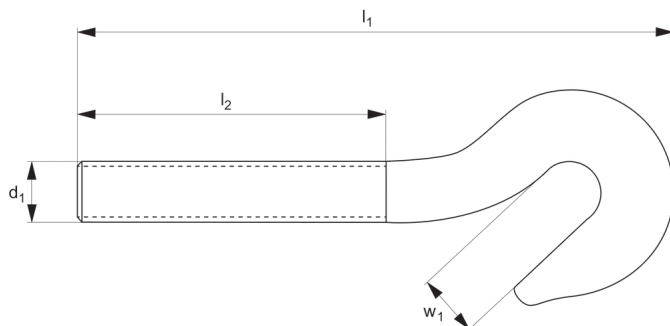

Hooks for Turnbuckles

steel

Turnbuckles

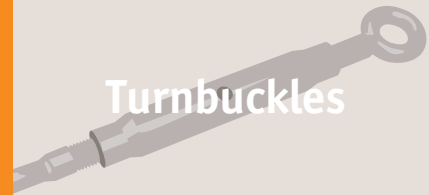

R3862

TURNBUCKLES

Material

Steel (1.0037).

Hot dip galvanized version, available on request providing increased protection

against corrosion. Please add -FZ for hot dip galvanized, e.g. R3862.R006-FZ.

Important Notes

Turnbuckles are not to be used for lifting. Only suitable for use in tension.

Order No.	Thread hand	d ₁	l ₁	l ₂	w ₁	S.W.L. kg	Weight kg
R3862.R006-ZP	Right	M 6	77.0	50	9.5	75	0.016
R3862.R008-ZP	Right	M 8	98.0	60	11.0	165	0.034
R3862.R010-ZP	Right	M10	116.5	73	14.0	235	0.060
R3862.R012-ZP	Right	M12	146.0	90	18.0	320	0.113
R3862.R014-ZP	Right	M14	140.0	80	16.0	420	0.170
R3862.R016-ZP	Right	M16	165.0	100	19.0	530	0.275
R3862.R020-ZP	Right	M20	180.0	105	21.0	730	0.440
R3862.R022-ZP	Right	M22	215.0	120	26.0	1120	0.685
R3862.R024-ZP	Right	M24	225.0	135	29.0	1550	0.765
R3862.R030-ZP	Right	M30	225.0	140	31.0	2240	1.325
R3862.R036-ZP	Right	M36	300.0	170	35.0	3530	2.285
R3862.L006-ZP	Left	M 6	77.0	50	9.5	75	0.016
R3862.L008-ZP	Left	M 8	98.0	60	11.0	165	0.034
R3862.L010-ZP	Left	M10	116.5	73	14.0	235	0.060
R3862.L012-ZP	Left	M12	146.0	90	18.0	320	0.113
R3862.L014-ZP	Left	M14	140.0	80	16.0	420	0.170
R3862.L016-ZP	Left	M16	165.0	100	19.0	530	0.275
R3862.L020-ZP	Left	M20	180.0	105	21.0	730	0.440
R3862.L022-ZP	Left	M22	215.0	120	26.0	1120	0.685
R3862.L024-ZP	Left	M24	225.0	135	29.0	1550	0.765
R3862.L030-ZP	Left	M30	225.0	140	31.0	2240	1.325
R3862.L036-ZP	Left	M36	300.0	170	35.0	3530	2.285

