
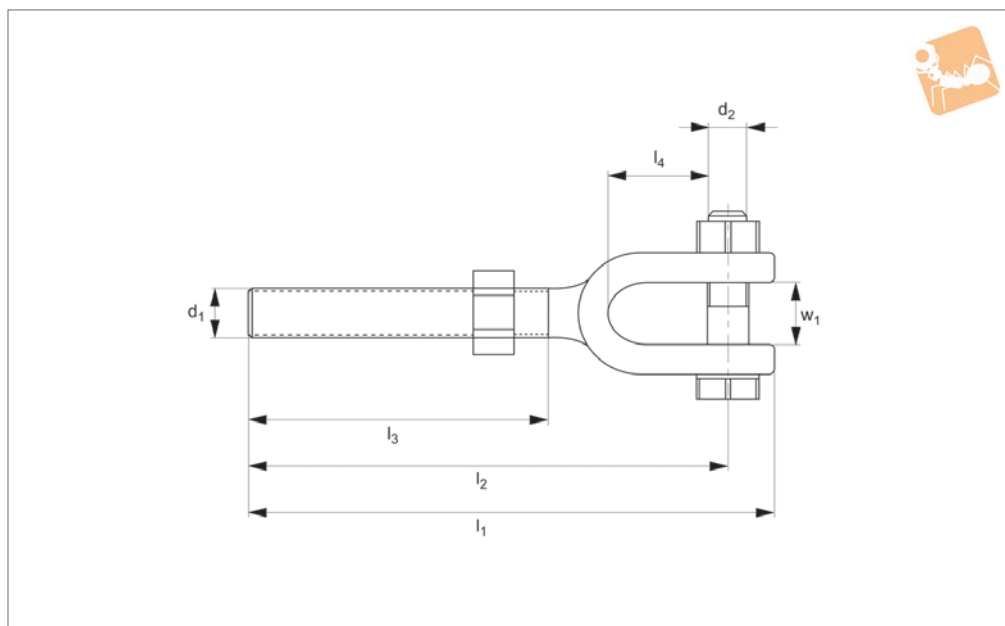


Jaws for Turnbuckles

steel

Turnbuckles

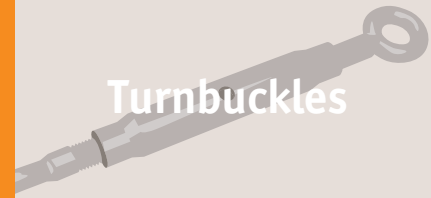

R3864

TURNBUCKLES

Material

Steel (C45, 1.0503), zinc-plated.
Hot dip galvanized version, above M12 available on request providing increased protection against corrosion. Please add -

FZ for hot dip galvanized, e.g. R3864.
R008-FZ.

Only suitable for use in tension.

Important Notes

Turnbuckles are not to be used for lifting.

Order No.	Thread hand	d ₁	d ₂	l ₁	l ₂	l ₃	l ₄	w ₁	Weight kg
R3864.R008-ZP	Right	M 8	8.5	125	116	68	28.75	9.0	0.095
R3864.R010-ZP	Right	M10	8.5	139	130	82	29.25	10.7	0.132
R3864.R012-ZP	Right	M12	10.5	160	150	90	44.75	15.5	0.215
R3864.R016-ZP	Right	M16	12.5	186	172	102	45.25	20.0	0.405
R3864.R020-ZP	Right	M20	17.0	205	185	115	59.50	23.5	0.812
R3864.R024-ZP	Right	M24	20.5	240	215	125	62.75	29.0	1.395
R3864.R030-ZP	Right	M30	25.0	290	255	150	89.50	34.0	2.690
R3864.L008-ZP	Left	M 8	8.5	125	116	68	28.75	9.0	0.095
R3864.L010-ZP	Left	M10	8.5	139	130	82	29.25	10.7	0.132
R3864.L012-ZP	Left	M12	10.5	160	150	90	44.75	15.5	0.215
R3864.L016-ZP	Left	M16	12.5	186	172	102	45.25	20.0	0.405
R3864.L020-ZP	Left	M20	17.0	205	185	115	59.50	23.5	0.812
R3864.L024-ZP	Left	M24	20.5	240	215	125	62.75	29.0	1.395
R3864.L030-ZP	Left	M30	25.0	290	255	150	89.5	34.0	2.690