





Ball Bearing - Wire imperial, ground raceway

Ring Bearings

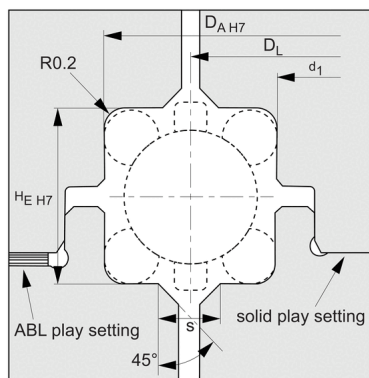

fitted dimensions

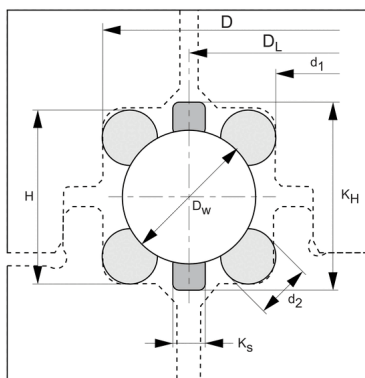

R4224.1

RING BEARINGS

Material

Hardened corrosion resistant steel wire and ball bearings (in plastic cage).

surface-solid settings or can be set by matching with spacers.

competitive. Please ask us to 'cross reference' if required.

Technical Notes

Play in the bearings can be adjusted via the

Tips

Our wire bearings are compatible with most other manufacturers and are very cost

Smaller sizes on previous page.

Order No.	d	H inch	H mm	Dyn. load C kN max.	Dyn. load C ₀ kN max.	Weight kg
R4224.1025	1012.05	0.51	12.95	46.4	317.8	2.15
R4224.1050	1037.05	0.51	12.95	47.0	325.5	2.21
R4224.1075	1062.05	0.51	12.95	47.5	333.3	2.26
R4224.1100	1087.05	0.51	12.95	48.1	341.0	2.31
R4224.1125	1112.05	0.51	12.95	48.6	348.8	2.36
R4224.1150	1137.05	0.51	12.95	49.2	356.5	2.42
R4224.1175	1162.05	0.51	12.95	49.7	364.3	2.47
R4224.1200	1187.05	0.51	12.95	50.2	372.0	2.52
R4224.1225	1212.05	0.51	12.95	50.8	379.8	2.57
R4224.1250	1237.05	0.51	12.95	51.3	387.5	2.63
R4224.1275	1262.05	0.51	12.95	51.8	395.3	2.68
R4224.1300	1287.05	0.51	12.95	52.3	403.0	2.73
R4224.1325	1312.05	0.51	12.95	52.8	410.8	2.78
R4224.1350	1337.05	0.51	12.95	53.3	418.5	2.84
R4224.1375	1362.05	0.51	12.95	53.8	426.3	2.89
R4224.1400	1387.05	0.51	12.95	54.3	434.0	2.94
R4224.1425	1412.05	0.51	12.95	54.7	441.8	2.99
R4224.1450	1437.05	0.51	12.95	55.2	449.5	3.05
R4224.1475	1462.05	0.51	12.95	55.7	457.3	3.10
R4224.1500	1487.05	0.51	12.95	56.2	465.0	3.15
R4224.1525	1512.05	0.51	12.95	56.6	472.8	3.20
R4224.1550	1537.05	0.51	12.95	57.1	480.5	3.26
R4224.1575	1562.05	0.51	12.95	57.5	488.3	3.31
R4224.1600	1587.05	0.51	12.95	58.0	496.0	3.36
R4224.1625	1612.05	0.51	12.95	58.5	503.8	3.41
R4224.1650	1637.05	0.51	12.95	58.9	511.5	3.47
R4224.1675	1662.05	0.51	12.95	59.3	519.3	3.52