




Ball Bearing - Wire, Duo Profile

duo-profile, drawn raceway

Ring Bearings

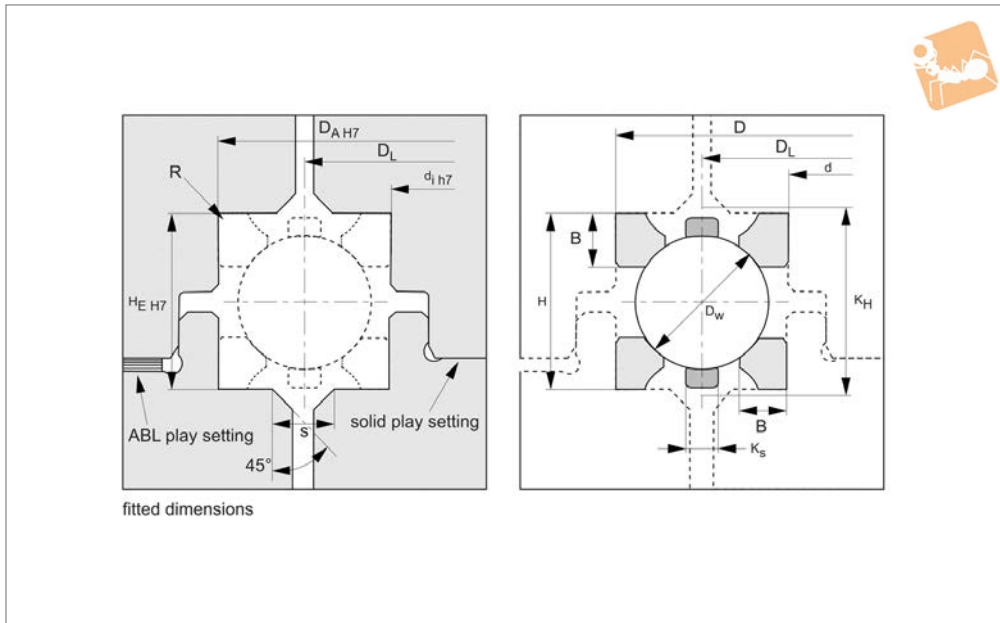

R4230

RING BEARINGS

Material

Hardened corrosion resistant steel wire and ball bearings (in plastic cage).

surface-solid settings or can be set by matching with spacers.

competitive. Please ask us to 'cross reference' if required.

Technical Notes


Play in the bearings can be adjusted via the

Tips

Our wire bearings are compatible with most other manufacturers and are very cost

Larger sizes on next page.

Order No.	d	DL	h	Load C ₀ kN	Dyn. load C kN max.	Weight kg
R4230.100	89	100	13	32.0	15.0	0.19
R4230.105	94	105	13	33.6	15.4	0.20
R4230.110	99	110	13	35.2	15.7	0.21
R4230.115	104	115	13	36.8	16.1	0.21
R4230.120	109	120	13	38.4	16.4	0.22
R4230.125	114	125	13	40.0	16.8	0.23
R4230.130	119	130	13	41.6	17.1	0.24
R4230.135	124	135	13	43.2	17.4	0.25
R4230.140	129	140	13	44.8	17.7	0.26
R4230.145	134	145	13	46.4	18.1	0.27
R4230.150	139	150	13	48.0	18.4	0.28
R4230.155	144	155	13	49.6	18.7	0.29
R4230.160	149	160	13	51.2	19.0	0.30
R4230.165	154	165	13	52.8	19.3	0.31
R4230.170	159	170	13	54.4	19.6	0.32
R4230.175	164	175	13	56.0	19.9	0.33
R4230.180	169	180	13	57.6	20.1	0.34
R4230.185	174	185	13	59.2	20.4	0.34
R4230.190	179	190	13	60.8	20.7	0.35
R4230.195	184	195	13	62.4	21.0	0.36
R4230.200	189	200	13	64.0	21.2	0.37
R4230.205	194	205	13	65.6	21.5	0.38
R4230.210	199	210	13	67.2	21.7	0.39
R4230.215	204	215	13	68.8	22.0	0.40
R4230.220	209	220	13	70.4	22.3	0.41
R4230.225	214	225	13	72.0	22.5	0.42
R4230.230	219	230	13	73.6	22.8	0.43
R4230.235	224	235	13	75.2	23.0	0.44
R4230.240	229	240	13	76.8	23.2	0.45
R4230.245	234	245	13	78.4	23.5	0.46
R4230.250	239	250	13	80.0	23.7	0.47

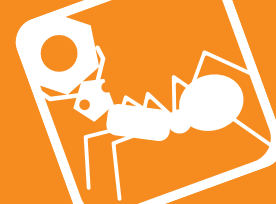

Order No.	d	D _L	h	Load C ₀ kN	Dyn. load C kN max.	Weight kg
R4230.255	244	255	13	81.6	24.0	0.47
R4230.260	249	260	13	83.2	24.2	0.48
R4230.265	254	265	13	84.8	24.4	0.49
R4230.270	259	270	13	86.4	24.7	0.50
R4230.275	264	275	13	88.0	24.9	0.51
R4230.280	269	280	13	89.6	25.1	0.52
R4230.285	274	285	13	91.2	25.3	0.53
R4230.290	279	290	13	92.8	25.6	0.54
R4230.295	284	295	13	94.4	25.8	0.55

RING BEARINGS