





Ball Bearing - Wire, Duo Profile

duo-profile, drawn raceway

Ring Bearings

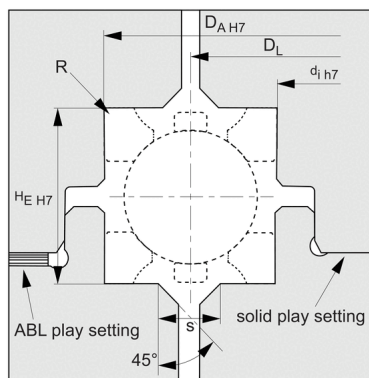

fitted dimensions

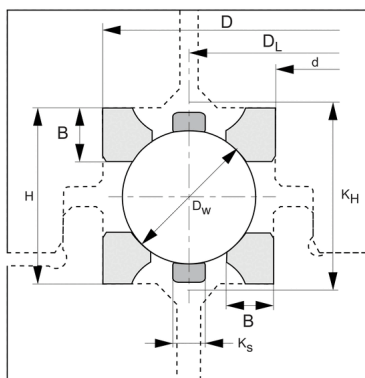

R4230.1

RING BEARINGS

Material

Hardened corrosion resistant steel wire and ball bearings (in plastic cage).

Technical Notes

Play in the bearings can be adjusted via the

surface-solid settings or can be set by matching with spacers.

Tips

Our wire bearings are compatible with most other manufacturers and are very cost

competitive. Please ask us to 'cross reference' if required.

Smaller sizes on previous page.

Order No.	d	D _L	h	Load C ₀ kN	Dyn. load C kN max.	Weight kg
R4230.300	289	300	13	96.0	26.0	0.56
R4230.310	299	310	13	99.2	26.4	0.58
R4230.320	309	320	13	102.4	26.8	0.60
R4230.330	319	330	13	105.6	27.2	0.61
R4230.340	329	340	13	108.8	27.7	0.63
R4230.350	339	350	13	112.0	28.1	0.65
R4230.360	349	360	13	115.2	28.5	0.67
R4230.370	359	370	13	118.4	28.9	0.69
R4230.380	369	380	13	121.6	29.2	0.71
R4230.390	379	390	13	124.8	29.6	0.73
R4230.400	389	400	13	128.0	30.0	0.74
R4230.410	399	410	13	131.2	30.4	0.76
R4230.420	409	420	13	134.4	30.8	0.78
R4230.430	419	430	13	137.6	31.1	0.80
R4230.440	429	440	13	140.8	31.5	0.82
R4230.450	439	450	13	144.0	31.8	0.84
R4230.460	449	460	13	147.2	32.2	0.86
R4230.470	459	470	13	150.4	32.5	0.87
R4230.480	469	480	13	153.6	32.9	0.89
R4230.490	479	490	13	156.8	33.2	0.91
R4230.500	489	500	13	160.0	33.5	0.93
R4230.510	499	510	13	163.2	33.9	0.95
R4230.520	509	520	13	166.4	34.2	0.97
R4230.530	519	530	13	169.6	34.5	0.99