




Ball Bearing - Wire, Duplex Profile

duplex profile, drawn raceway

Ring Bearings

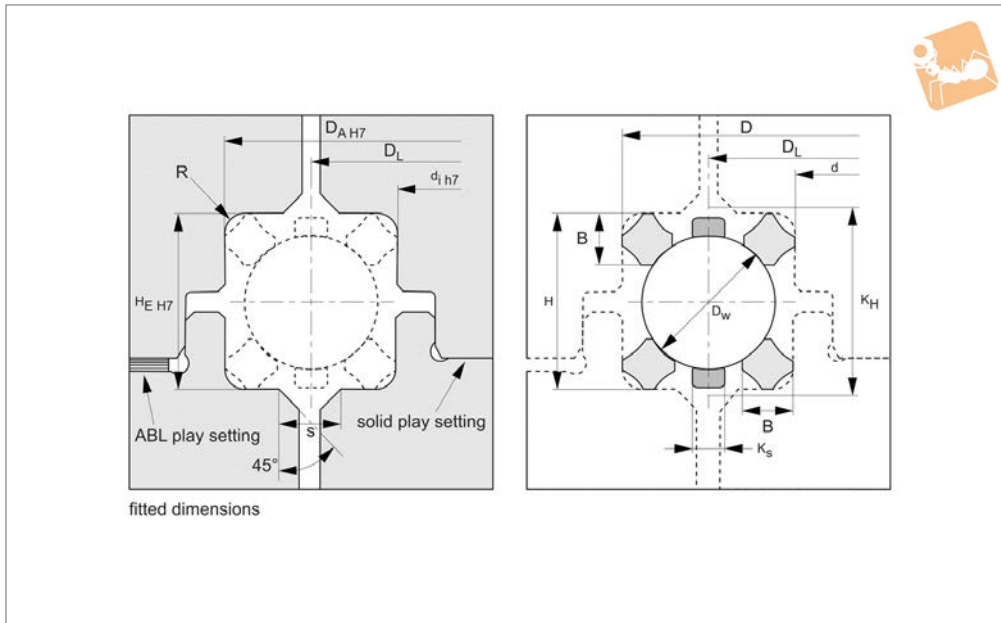

R4240.1

RING BEARINGS

Material

Hardened corrosion resistant steel wire and ball bearings (in plastic cage).

surface-solid settings or can be set by matching with spacers.

competitive. Please ask us to 'cross reference' if required.

Technical Notes

Play in the bearings can be adjusted via the

Tips

Our wire bearings are compatible with most other manufacturers and are very cost

Smaller sizes on previous page.

Order No.	d	D _L	h	Dyn. load C kN max.	Dyn. load C ₀ kN max.	Weight kg
R4240.0300	287.05	300	12.95	26.0	96.0	0.59
R4240.0310	297.05	310	12.95	26.4	99.2	0.61
R4240.0320	307.05	320	12.95	26.8	102.4	0.63
R4240.0330	317.05	330	12.95	27.2	105.6	0.65
R4240.0340	327.05	340	12.95	27.7	108.8	0.67
R4240.0350	337.05	350	12.95	28.1	112.0	0.69
R4240.0360	347.05	360	12.95	28.5	115.2	0.71
R4240.0370	357.05	370	12.95	28.9	118.4	0.73
R4240.0380	367.05	380	12.95	29.2	121.6	0.75
R4240.0390	377.05	390	12.95	29.6	124.8	0.76
R4240.0400	387.05	400	12.95	30.0	128.0	0.78
R4240.0410	397.05	410	12.95	30.4	131.2	0.80
R4240.0420	407.05	420	12.95	30.8	134.4	0.82
R4240.0430	417.05	430	12.95	31.1	137.6	0.84
R4240.0440	427.05	440	12.95	31.5	140.8	0.86
R4240.0450	437.05	450	12.95	31.8	144.0	0.88
R4240.0460	447.05	460	12.95	32.2	147.2	0.90
R4240.0470	457.05	470	12.95	32.5	150.4	0.92
R4240.0480	467.05	480	12.95	32.9	153.6	0.96
R4240.0490	477.05	490	12.95	33.2	156.8	0.96
R4240.0500	487.05	500	12.95	33.5	160.0	0.98
R4240.0510	497.05	510	12.95	33.9	163.2	1.00
R4240.0520	507.05	520	12.95	34.2	166.4	1.04
R4240.0530	517.05	530	12.95	34.5	169.6	1.04